

UNITAP™
THE MOLE™ Direct Burial
 In-Line Splice/Reducer



Designed specifically for direct burial applications, the MOLE™ in-line splice/reducer is made with a specialized plastisol material that forms a rugged weathertight connection.

Catalog Number	Number of Ports	Wire Range (AWG/kcmil)	L	W	H	Hex Key
BISR4-DB	2	#6 AWG-#4 AWG	4.30	0.68	1.39	1/8
BISR1-DB	2	#2 AWG-#1 AWG	6.30	0.88	1.75	5/32
BISR3/0-DB	2	1/0 -3/0 AWG	6.25	0.99	1.96	3/16
BISR250-DB	2	4/0 AWG-250 kcmil	6.70	1.18	2.17	5/16


UNITAP™
Direct Burial Connectors
 Dual Rated Multiple Tap



Rubberinsulated, dualrated multi-tap connectors. No taping or heat shrink required. Supplied with aluminum set-screws, covered in high quality EPDM rubber. Supplied with oxide inhibitor pre-installed. Submersible rated, suitable for direct burial, UL Listed, CSA Certified. For use in wet or damp locations.

Catalog Number	# of Ports	Wire Range (AWG/kcmil)	L	W	H
BIBS3502DB	2	12 AWG-350 kcmil	2.61	4.06	2.46
BIBS3503DB	3	12 AWG-350 kcmil	3.82	4.06	2.46
BIBS3504DB	4	12 AWG-350 kcmil	5.03	4.06	2.46
BIBS3505DB	5	12 AWG-350 kcmil	6.24	4.06	2.46
BIBS3506DB	6	12 AWG-350 kcmil	7.45	4.06	2.46
BIBS5003DB	3	10 AWG-500 kcmil	4.31	4.58	3.13
BIBS5004DB	4	10 AWG-500 kcmil	5.69	4.58	3.13
BIBS5005DB	5	10 AWG-500 kcmil	7.06	4.58	3.13
BIBS5006DB	6	10 AWG-500 kcmil	8.44	4.58	3.13

Torque Wrenches make sure you've got it torqued right!

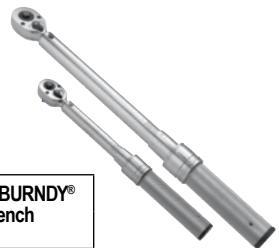

Recommended Torque Values for Direct Burial UNITAP™		Recommended BURNDY® Torque Wrench
Conductor Size	Recommended Torque Range	
#12 - #6 AWG	125 - 150 in-lbs	BTW30150
#4 - 3/0 AWG	180 - 240 in-lbs	BTW150750
4/0 - 350 AWG	275 - 450 in-lbs	BTW150750
400 - 1000 AWG	475 - 550 in-lbs	BTW150750