



Nonmetallic - Strut systems

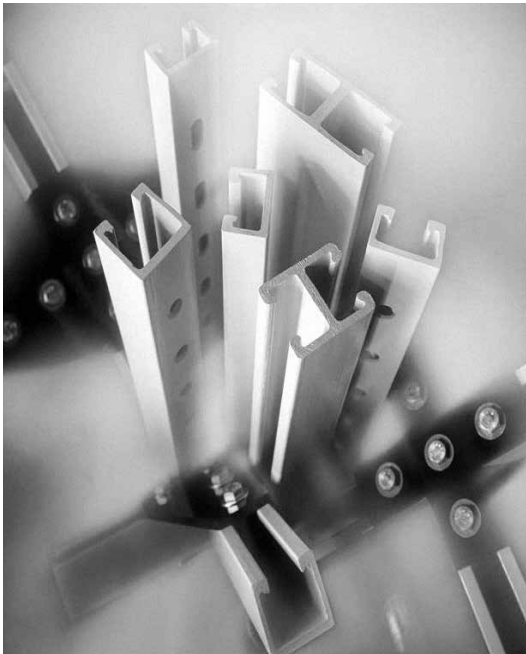
Channels

Channels

ABB is proud of its line of nonmetallic strut and accessories. You'll find a complete selection of nonmetallic accessories, fasteners, hangers, pipe clamps and channels.

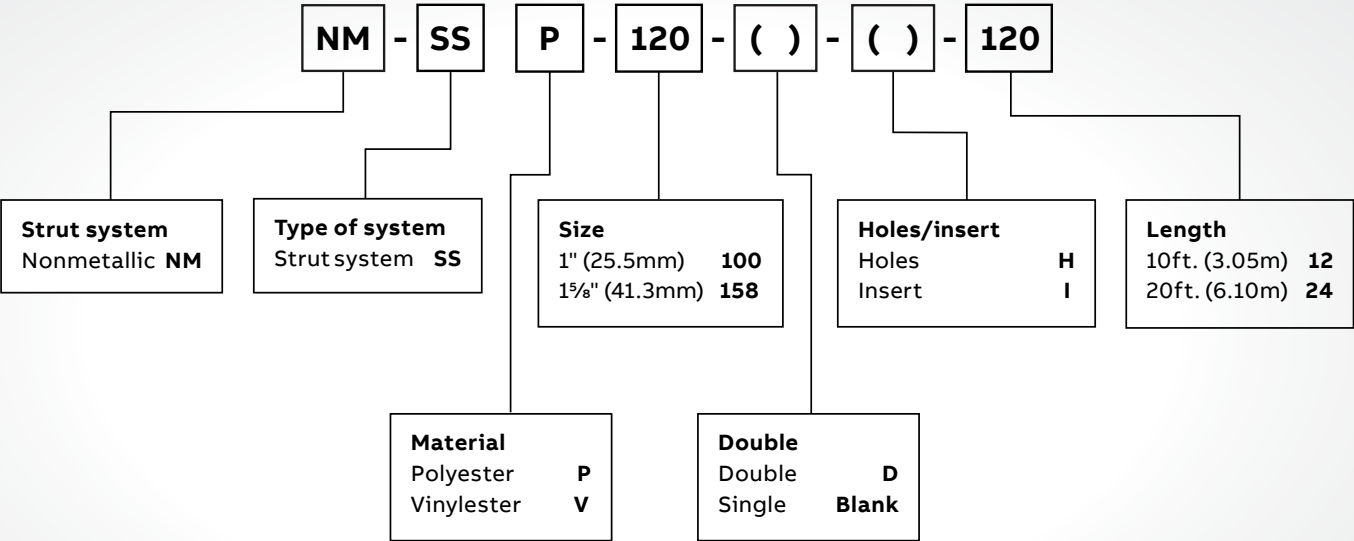
Most ABB strut products are available in a choice of resins – either vinylester or polyester. Our design and engineering staff is ready to help you select the material that best suits your needs.

Channel fitting selection



Example:
NM-SSP-100-120, 1" (25.5mm) single strut, 120" (10 ft. / 3.05m) NOTE: Stocked in 120" (10 ft. / 3.05m) and 240" (20 ft. / 6.10m) lengths.

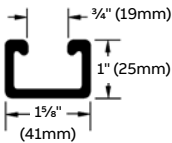
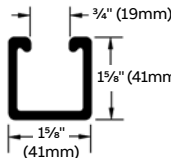
*NOTE: The U-style and H-style systems are interchangeable.



Nonmetallic - Strut systems

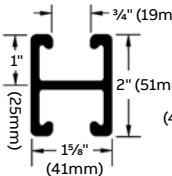
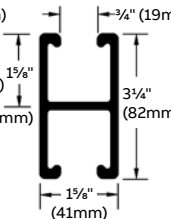
Channels - Combinations and hole pattern

Solid - Single strut

					Weight	
		Cat. No.	Material/resin	Color	(lb/ft.)	(kg/m)
	NM-SS(*)-100	NM-SSP-100-(L)	Polyester	Gray	0.47	0.70
		NM-SSP-158-(L)	Polyester	Gray	0.63	0.94
		NM-SSV-100-(L)	Vinylester	Beige	0.47	0.70
		NM-SSV-158-(L)	Vinylester	Beige	0.63	0.94

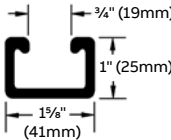
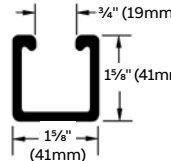
*Add P for polyester or V for vinylester.
(L) Add desired length 120 (10 ft.) or 240 (20 ft.)
Cut-to-length channel also available.

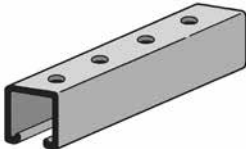
Solid - Back to back

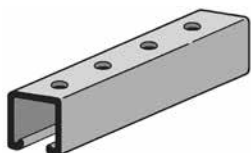
					Weight	
		Cat. No.	Material/resin	Color	(lb/ft.)	(kg/m)
	NM-SS(*)-100-D	NM-SSP-100-D-(L)	Polyester	Gray	0.86	1.28
		NM-SSP-158-D-(L)	Polyester	Gray	1.17	1.75
		NM-SSV-100-D-(L)	Vinylester	Beige	0.86	1.28
		NM-SSV-158-D-(L)	Vinylester	Beige	1.17	1.75

*Add P for polyester or V for vinylester.
(L) Add desired length 120 (10 ft.) or 240 (20 ft.)
Cut-to-length channel also available.

Punched

						Weight
		Cat. No.	Material/resin	Color	(lb/ft.)	(kg/m)
		NM-SSP-100-H-(L)	Polyester	Gray	0.47	0.67
		NM-SSP-158-H-(L)	Polyester	Gray	0.63	0.91
		NM-SSV-100-H-(L)	Vinylester	Beige	0.45	0.67
		NM-SSV-158-H-(L)	Vinylester	Beige	0.61	0.91





Holes - 5/16" holes x 1 7/8" on center.
(L) Add desired length 120 (10 ft.) or 240 (20 ft.)
Cut-to-length channel also available.