



Trac 12™ Linear Lighting

Thanks to its ultra-slim profile, Trac 12 can be easily installed in covers, cabinetry, and casework displays to produce uniform linear lighting. Variable spacing of either LED modules or xenon lampholders permits on-site fine tuning to create even illumination at the desired light intensity.



Photo Credit: Pictureboy Photography



TL103L



TL103

LED Mini-Flood

The Trac 12 LED Mini-Flood offers effective flood and task lighting in a low-profile, energy-efficient package. Consuming only 4 watts of power, it approximates the lumen output and light distribution of 20W halogen, using less than 25% of the energy while providing a rated life of 50,000 hours.

TL103L

Color Temp.	CRI	Dimensions	Finishes
30K 3000K 40K 4000K	80CRI 90 CRI		Black (BL) White (WH) Silver (SL)

Halogen Flood

The Trac 12 Halogen Flood is available with either 10W or 20W halogen lamps to suit a wide variety of applications. Lamp service life is rated at 2,000 hours. The Halogen Flood operates on any 12-volt or 24-volt, Trac 12 or Trac 12/25 transformer, adding to its specification flexibility.

TL103

Lamp	Dimensions	Finishes
12V or 24V 10-20W T3 halogen bi-pin lamp		Black (BL) White (WH)

T3 Halogen Bi-Pin Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL923	12	20	Clear	307

Juno® Trac 12™ Linear Lighting



Wedge Base


Wedge base lampholders are compatible with wedge base lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

TL201

Lamp

One 12V or 24V, 10W max. T3-1/4 wedge base lamp

 Dimensions



Finishes



Black (BL)




White (WH)

TL202

Lamp

Two 12V or 24V, 10W max. T3-1/4 wedge base lamps

 Dimensions



Finishes



Black (BL)



White (WH)

Xenon T3-1/4 Wedge Base Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL900 CLR	12	3	Clear	15
TL901 CLR	12	5	Clear	33
TL903 CLR	12	10	Clear	83
TL905 FRST 24	24	5	Frosted	29
TL910 FRST 24	24	10	Frosted	91

Rigid Loop


The rigid loop lampholder includes a stationary reflector to forward project more of the 360° light from the lamp. They are compatible with rigid loop style lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. Rigid loop lamps possess all of the advantages of the wedge base lamps, but offer a more symmetrical light distribution and slightly higher output that is optimal for cove lighting applications. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

TL211

Lamp

One 12V or 24V, 10W max. T3-1/4 rigid loop lamp

 Dimensions



Finishes



Black (BL)



White (WH)

Xenon T3-1/4 Rigid Loop Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL950 CLR	12	5	Clear	45
TL950 FRST	12	5	Frosted	45
TL951 CLR	12	10	Clear	100
TL951 FRST	12	10	Frosted	100
TL952 CLR 24	24	5	Clear	40
TL952 FRST 24	24	5	Frosted	40
TL953 CLR 24	24	10	Clear	90
TL953 FRST 24	24	10	Frosted	90

Festoon


The festoon lampholder includes an articulating reflector, enabling more precise aiming of the light. They are compatible with festoon type lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. The festoon lamp is similar to the rigid loop lamp, though more widely available and offering slightly greater light output. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

TL212

Lamp

One 12V or 24V, 10W max. T3-1/4 festoon lamp

Dimensions

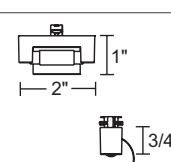

Finishes



White (WH)

Xenon T3-1/4 Festoon Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL960 CLR	12	5	Clear	50
TL960 FRST	12	5	Frosted	50
TL961 CLR	12	10	Clear	120
TL961 FRST	12	10	Frosted	120
TL964 CLR 24	24	5	Clear	50
TL964 FRST 24	24	5	Frosted	50
TL965 CLR 24	24	10	Clear	120
TL965 FRST 24	24	10	Frosted	120



©2017 Acuity Brands Lighting, Inc. The marks appearing in this catalog are trademarks of Acuity Brands Lighting, Inc. Products shown in this brochure may be covered by U.S. and international patents and patents pending. Specifications subject to change without notice. Printed in the U.S.A.