

# M18 FUEL™ STRING TRIMMER w/ QUIK-LOK™

2825-21ST, 2825-20ST




QUIK-LOK™ ATTACHMENT  
CAPABLE




REDLITHIUM  
HD9.0

## MORE POWER

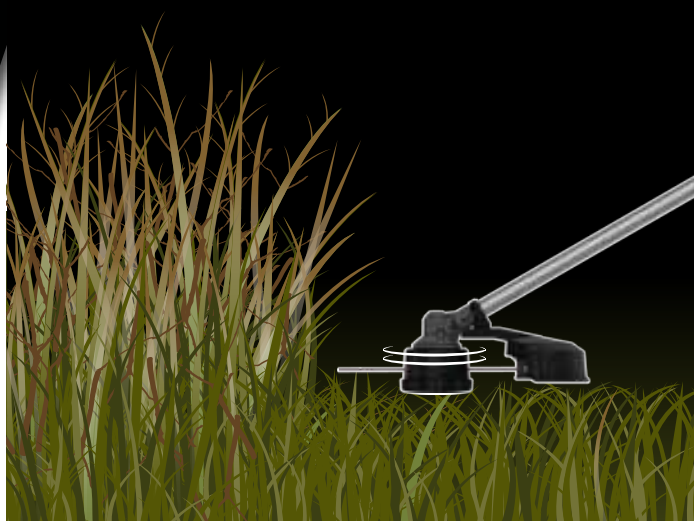

**POWER  
TO CLEAR  
THICK BRUSH**

## FASTER ACCELERATION

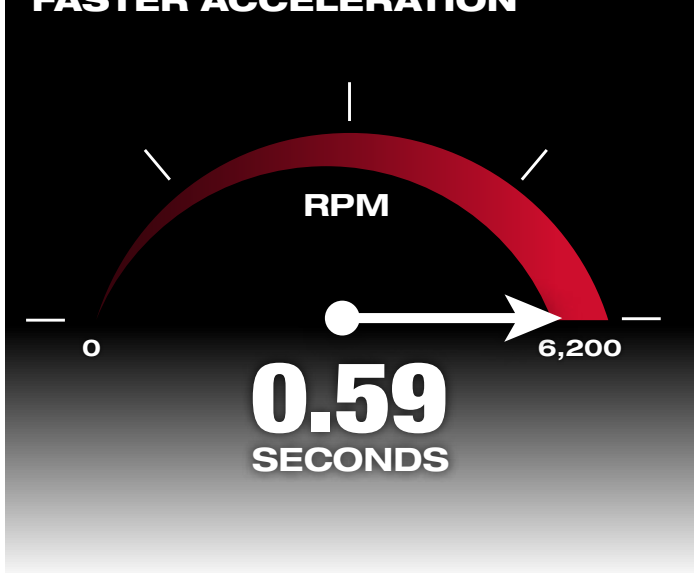

**FULL THROTTLE  
UNDER  
1 SECOND**

## MORE WORK PER CHARGE



**UP TO  
1 HOUR  
PER CHARGE**

## String Trimmer w/ QUIK-LOK™

DESCRIPTION	SPECIFICATIONS
Cutting Swath	14" – 16"
Line Diameter	.080" / .095"
RPM	0 – 4,900 / 0 – 6,200
Trigger	Variable Speed
Feed System	Bump Feed
Length	73.6"
Weight	12.3 lbs



### 2825-21ST M18 FUEL™ String Trimmer Kit w/ QUIK-LOK™

Includes: 2825-20 M18 FUEL™ Power Head w/ QUIK-LOK™, 49-16-2717 QUIK-LOK™ String Trimmer Attachment, M18™ REDLITHIUM™ HD9.0 Battery Pack, M18™ and M12™ Rapid Charger

**SHOP NOW**



### 2825-20ST M18 FUEL™ String Trimmer w/ QUIK-LOK™ (Tool-Only)

Includes: 2825-20 M18 FUEL™ Power Head w/ QUIK-LOK™, 49-16-2717 QUIK-LOK™ String Trimmer Attachment

**SHOP NOW**

# M18 FUEL™ 10" POLE SAW w/ QUIK-LOK™

2825-21PS



QUIK-LOK™ ATTACHMENT  
CAPABLE




REDLITHIUM™  
HD9.0

MORE POWER



**POWER  
TO CUT  
HARDWOODS**

FASTER ACCELERATION

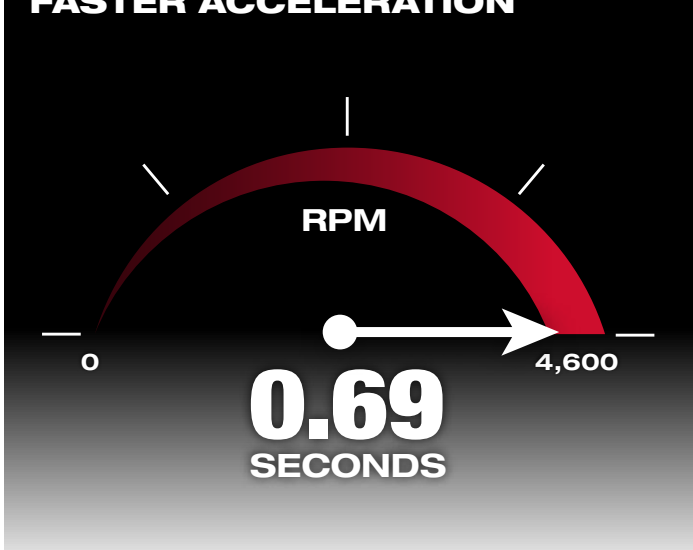

**FULL THROTTLE  
UNDER  
1 SECOND**

INCREASED PRODUCTIVITY



**UP TO  
150 CUTS  
PER CHARGE**

## 10" Pole Saw w/ QUIK-LOK™

DESCRIPTION	SPECIFICATIONS
RPM	0 – 4,600
Bar Length	10"
Chain Gauge	.043"
Chain Pitch	3/8" Low Profile™
Length	84.0"
Weight	12.7 lbs



### 2825-21PS M18 FUEL™ 10" Pole Saw Kit w/ QUIK-LOK™

Includes: 2825-20 M18 FUEL™ Power Head w/ QUIK-LOK™, 49-16-2720 QUIK-LOK™ 10" Pole Saw Attachment, 49-16-2721 QUIK-LOK™ 3' Attachment Extension, M18™ REDLITHIUM™ HD9.0 Battery Pack, M18™ and M12™ Rapid Charger, OREGON® Bar and Chain, Srench

Bar and Chain Oil Sold Separately

**SHOP NOW**


# M18 FUEL™

## 16" CHAINSAW


2727-21HD, 2727-20



**REDLITHIUM™**  
HIGH OUTPUT™ HD12.0

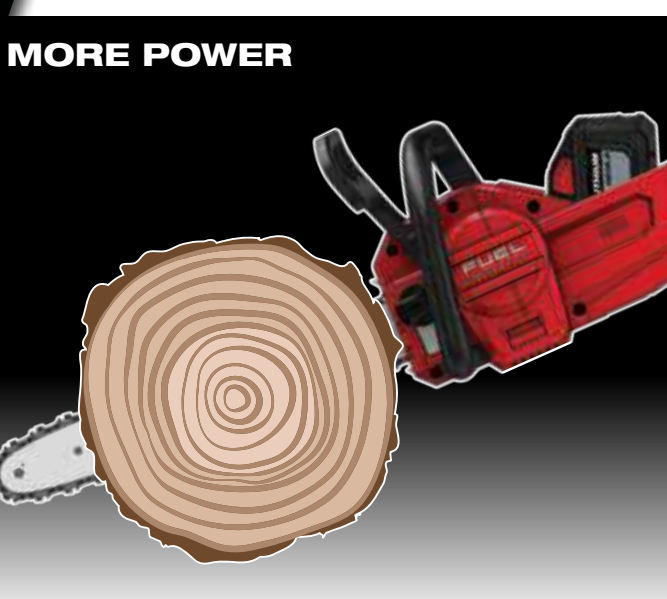

**POWER**  
TO CUT  
HARDWOODS

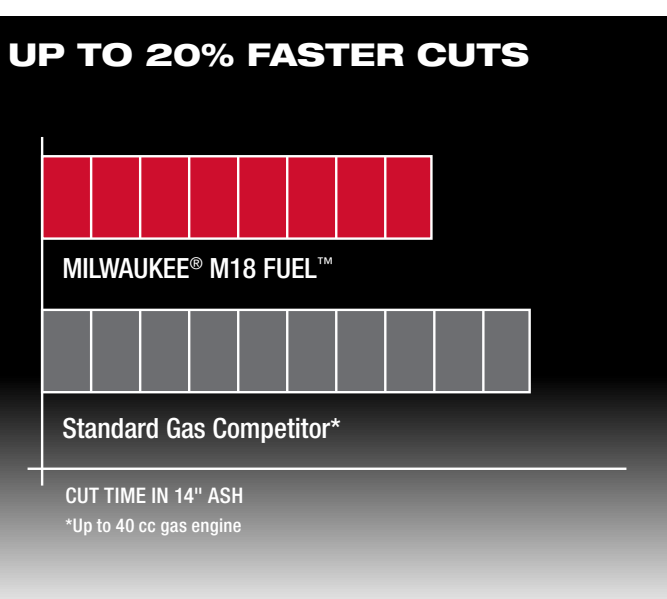

**FASTER**  
THAN  
GAS



UP TO  
**150 CUTS**  
PER CHARGE

### 16" Chainsaw

DESCRIPTION	SPECIFICATIONS
RPM	6,600
Bar Length	16"
Chain Gauge	.043"
Chain Pitch	3/8" Low Profile™
Trigger	Variable Speed
Length	33.0"
Weight	13.9 lbs



#### 2727-21HD M18 FUEL™ 16" Chainsaw Kit

Includes: 2727-20 M18 FUEL™ 16" Chainsaw, (1) M18™ REDLITHIUM™ HIGH OUTPUT™ HD12.0 Battery Pack, M18™ and M12™ Rapid Charger, Oregon® Bar and Chain, Scrench

Bar and Chain Oil Sold Separately

**SHOP NOW**



#### 2727-20 M18 FUEL™ 16" Chainsaw (Tool-Only)

Includes: 2727-20 M18 FUEL™ 16" Chainsaw, Oregon® Bar and Chain, Scrench

Bar and Chain Oil Sold Separately

**SHOP NOW**