

# SLIM DISK LED

6" Round Slim LED with Easy Color SeleCCTor

Catalog Number:


Project Name:

Note:

Type:

## 6" ROUND SLIM LED BAFFLE


NEW

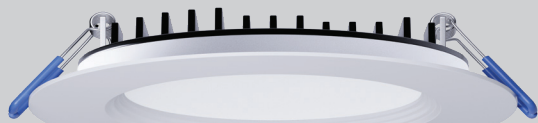

700L

EASY 5 COLORS  
SELE<sup>CCT</sup>OR

### DIMENSIONS

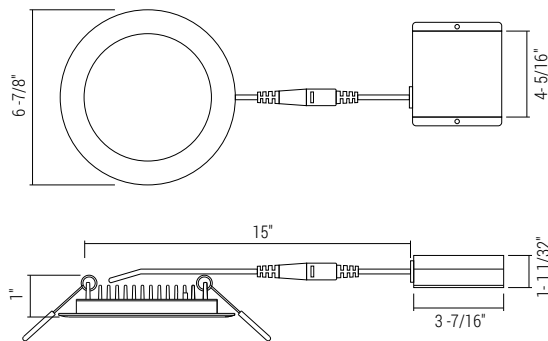

### SPECIFICATIONS:

APERTURE	6"
LUMENS	700 lumens
WATTAGE	12W
CCT	27K/30K/35K/40K/50K
CRI	90
VOLTAGE	120V
POWER FREQUENCY	60 Hz
FINISH	White
AMBIENT ENVIRONMENT	Damp location approved

### FEATURE

Round 6" fixtures with integral LEDs. One driver for every fixture required. PF>0.95. Maximum number of fixtures per standard 150W LED dimmer: 12

Dimmable

ETL Approved and Energy Star Certified

Damp location approved

Pot light housing is not required even for insulated ceilings

Fast and easy to install in limited space locations

External driver factory mounted inside connector box

New construction rough-in plates and jumper cables available

Available in 5 Color Temperatures ( 2700K, 3000K, 3500K, 4000K and 5000K)

50,000 Hours Life

### TECHNICAL SPECIFICATIONS

WATTAGES: 12W

OUTPUT: Default Driver Voltage: 120V AC 60 Hz (Dimmable)

OPTICS: 120°

CRI: 90+

AMBIENT TEMPERATURE: -40°F (-40°C) to +104°F (+40°C)

### LISTING

Energy Star

ETL listed for Damp location



Ordering Information: Example: RL679-700L-DIMTR-120-27K/30K/35K/40K/50K-90-WH



SERIES/APERTURE/LUMENS

RL679-700L - 700 lumens



DIMMING

DIMTR - Triac



VOLTAGE

120 - 120V



CCT

27K/30K/35K/40K/50K



CRI

90 - 90+ CRI



FINISH

WH - White



ACCESSORIES

RL-ACC-SLIM-1-10F  
RL-ACC-SLIM-1-20F  
RL-ACC-SLIM-6-ROUGHPLATE



Submittal form is available @ [www.iuseeliteled.com](http://www.iuseeliteled.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions  
subject to change without notice.

# SLIM DISK LED

6" Round Slim LED with Easy Color SeleCCTor

6" ROUND SLIM LED BAFFLE

Catalog Number:	
Project Name:	
Note:	Type:


## ACCESSORIES



RL-ACC-SLIM-1-10F  
10-ft long extension



RL-ACC-SLIM-1-20F  
20-ft long extension

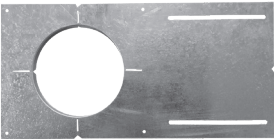

RL-ACC-SLIM-6-ROUGHPLATE  
Rough Plate