

STRING LIGHT AND TROUBLE LIGHT

Our String and Trouble Lights were designed to provide temporary lighting in tough environments, whether you need lighting for a wide area or to perform a specific task. The String Lights are offered in lengths of 50' (15 m) and 100' (30 m) and are made of 12 or 14 AWG cable, which allows for them to be daisy-chained. The Trouble Light provides direct lighting for a smaller, specific area. It can be hung using the hook, leaving your hands free while performing a task. Multiple Trouble Lights can also be easily daisy-chained using the receptacle on the handle.

FEATURES AND SPECIFICATIONS

• String Light

Construction

- Color: Yellow
- Lamp guard material: Plastic

Wire Specifications

- Length: 50' (15 m) or 100' (30 m)
- SJTW 12 AWG / 3C or SJTW 14 AWG / 3C
- NEMA 5-15

Technical specifications

- Heavy duty E26 sockets handle up to 150 W
- Daisy-chain capability
- Suitable for use in dry locations

Ambient temperature

-40°C - +60° C

Compliances

- ETL

• Trouble Light

Construction

- Housing color: Orange
- Lamp guard material: Metal
- Built-in hanging hook
- On/Off switch on handle

Wire Specifications

- Length: 25' (7.5 m)
- SJTW 16 AWG / 3C
- NEMA 5-15

Technical specifications

- Heavy duty socket can handle up to 75 W
- Daisy-chain capability using receptacle on handle
- Suitable for use in dry locations

Ambient temperature

-40°C - +60°C

Compliances

- ETL



String Light



Trouble Light



QUICK SHIP AND TECHNICAL SPECIFICATION TABLE 🕒¹

Order code	Part number	Wire Length ft. (m)	Wire	Maximum Watts per Socket (W)	Volts		Amperage (A)	Socket	Number of Sockets	Lamp Guard Material	Case qty (master)	
					(Sockets)	(String)						
String Light												
66850	SL/50FT/DSC/5SKT/12AWG/PLASTIC/YL/STD	50 (15)	SJTW 12 AWG / 3C	150	120	125	12	E26	5	Plastic	1	
66851	SL/100FT/DSC/10SKT/12AWG/PLASTIC/YL/STD	100 (30)	SJTW 12 AWG / 3C	150	120	125	12	E26	10	Plastic	1	
67770	SL/100FT/DSC/10SKT/14AWG/PLASTIC/YL/STD	100 (30)	SJTW 14 AWG / 3C	150	120	125	12	E26	10	Plastic	1	
Trouble Light												
66852	TL/25FT/DSC/16AWG/METAL/OR/STD	25 (7.6)	SJTW 16 AWG / 3C	75	120	125	10	E26	1	Metal	12	

¹ **QUICK SHIP:** Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.

ACCESSORIES FOR STRING LIGHTS (order separately)

Order code	Part number	Type	Case qty (master)
66853	SL/CAGE/PLASTIC/YL/STD	Plastic Cage Replacement	50
66854	SL/SHOOK/METAL/STD 5P	Metal S Hooks (Pack of 5)	100

REPLACEMENT PLASTIC CAGE




S HOOKS




DIMENSIONS

STRING LIGHTS (50')

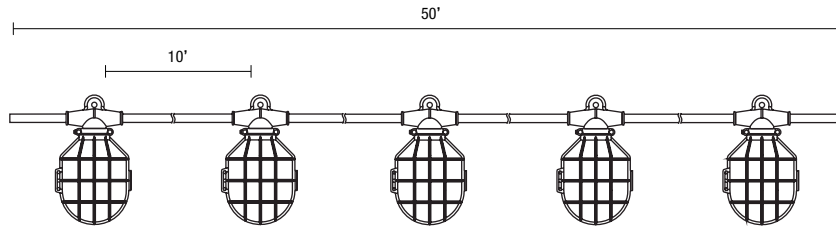


STRING LIGHTS (100')

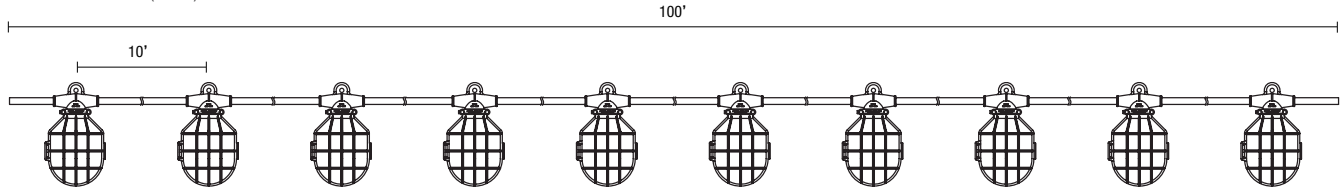

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions. All products are subject to change or may be discontinued any time without notice.

DIMENSIONS (cont'd)

TROUBLE LIGHT

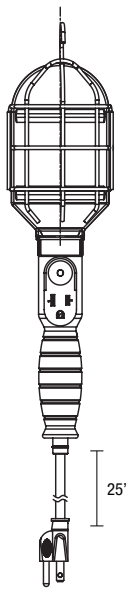

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions.
All products are subject to change or may be discontinued any time without notice.