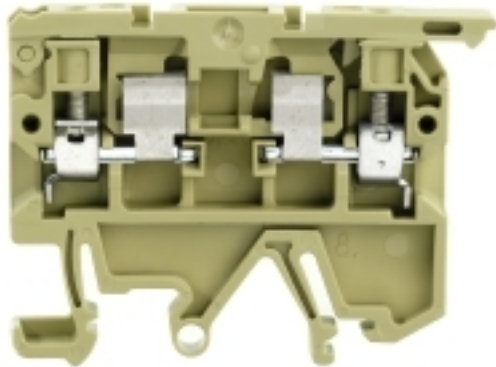


SAK Series
ASK1EN/SMT 10-60VUC BFI H-**Weidmüller Interface GmbH & Co. KG**
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com**Product image**

Similar to illustration

Klippon® Connect with clamping yoke Technology

The high reliability and variety of designs of the terminal blocks with clamping yoke connections make planning easier and optimises operational safety. Klippon® Connect provides a proven response to a range of different requirements.

General ordering data

| | |
|---------------------|--|
| Available until | 2016-01-01 |
| Type | ASK1EN/SMT 10-60VUC BFI H- |
| Order No. | 0222760001 |
| Version | SAK Series, Fuse terminal, Rated cross-section: 4 mm ² , Screw connection |
| GTIN (EAN) | 4032248730926 |
| Qty. | 100 pc(s). |
| Alternative product | 1119840000 |

Creation date September 2, 2020 6:57:16 AM CEST

Catalogue status 28.08.2020 / We reserve the right to make technical changes.

SAK Series ASK1EN/SMT 10-60VUC BFI H-

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|---------|-----------------|------------|
| Width | 8.1 mm | Width (inches) | 0.319 inch |
| Height | 58 mm | Height (inches) | 2.283 inch |
| Depth | 43 mm | Depth (inches) | 1.693 inch |
| Net weight | 12.94 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|--------|
| Storage temperature, max. | 55 °C | Storage temperature, min. | -25 °C |
| Storage temperature | -25 °C...55 °C | Continuous operating temp., min. | -50 °C |
| Continuous operating temp., max. | 100 °C | | |

Material data

| | | | |
|----------|-------|---------------------------|-----|
| Material | PA 66 | UL 94 flammability rating | V-2 |
|----------|-------|---------------------------|-----|

System specifications

| | | | |
|-------------------------------------|---|-----------------------------------|--------------|
| Version | Screw connection, Fuse cartridge, One end without connector | Number of levels | 1 |
| Number of clamping points per level | 2 | Levels cross-connected internally | No |
| PE connection | No | Rail | TS 35, TS 32 |

Additional technical data

| | |
|------------------|---------|
| Type of mounting | Snap-on |
|------------------|---------|

Conductors for clamping (rated connection)

| | | | |
|-----------------------|---|--------------------|------------------|
| Number of connections | 2 | Type of connection | Screw connection |
|-----------------------|---|--------------------|------------------|

Rating data

| | | | |
|--|-------------------|---|--------|
| Rated cross-section | 4 mm ² | Rated voltage | 60 V |
| Volume resistance according to IEC 60947-7-x | 1 mΩ | Power loss in accordance with IEC 60947-7-x | 1.02 W |

Classifications

| | | | |
|-------------|-------------|------------|-------------|
| ETIM 6.0 | EC000899 | ETIM 7.0 | EC000899 |
| eClass 9.0 | 27-14-11-16 | eClass 9.1 | 27-14-11-16 |
| eClass 10.0 | 27-14-11-16 | | |

Approvals

| | |
|-----------|---|
| Approvals |  |
| ROHS | Conform |

Data sheet**SAK Series
ASK1EN/SMT 10-60VUC BFI H-**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data**Downloads**

Approval/Certificate/Document of
Conformity

[EAC certificate](#)

User Documentation

[StorageConditionsTerminalBlocks](#)

Safety note

Safety notice

[Safety Information](#)