

# Technical Information Bulletin

## FLUO LED



Date: \_\_\_\_\_ Name of distributor: \_\_\_\_\_  
 In hands date of project: \_\_\_\_\_ Client #: \_\_\_\_\_  
 Project name/Number: \_\_\_\_\_ Name of end user: \_\_\_\_\_

### ORDERING INFORMATION

**Order code:** 67259  
**Description:** UCFL/60IN/120V/25W/30K/FR/WH/STD  
**UPC:** 69549672598  
**Case quantity:** 20

### PHYSICAL DATA

**Type:** FLUO LED  
**Length in (mm):** 60 (1524)  
**Shape:** Linear  
**Housing Material:** Aluminum  
**Finish:** White  
**Lens Finish:** Frosted  
**Mounting:** Surface  
**Daisy chain installation:** 12 units (300 W) can be installed in row




### PERFORMANCE DATA

**Watts (W):** 25  
**Volts (VAC):** 120  
**Colour temp. (K):** 3 000  
**Lumen output (lm):** 2 000  
**Lumen per Watts (lm/W):** 80  
**CRI:** 90  
**Life L70 (h):** 50 000  
**Beam angle (°):** 120  
**THD (%):** <0.15  
**Power factor:** 0.95  
**Dimming:** Forward AND Reverse  
**Operating temp. range:** -20°C to 40°C (-4°F to 104°F)

<sup>1</sup> Initial lumens range: +/- 5%  
<sup>2</sup> Typical colour temperature range: +/- 5%  
<sup>3</sup> Life hours are derived from IESNA LM80-08 testing report and projected per IESNA TM-21-11 extrapolations



### TECHNICAL DRAWINGS AND DIMENSIONS

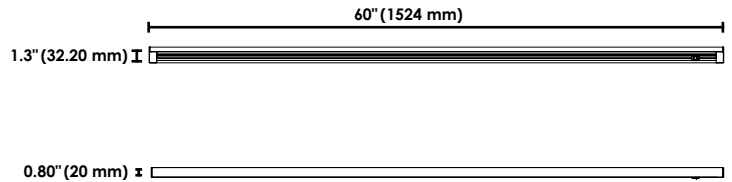

### COMPATIBLE DIMMERS

Brand	Model
LEGRAND	PD-5NE, RH703PTUTC
LUTRON	PD-6WCL, DVCL-153P, CTCL-153P, DVCL-253P, AYCL-253P, DVRP-253P-WH, SELV-300P, MACL-153P
COOPER	RRD-6NA-WH, SCL03P
LEVITON	6615, IPL06, 6674, DSL06-1LZ, DSM10-1LZ, IPE04-1LZ, DDMX1

### COMPATIBLE ACCESSORIES

Order code	Description	Type
67787	UC/HARDWIREBOX/120V/STD	Hardwire Box
67202	UCS/PLUG/120V/STD	120 V Power Cord Plug
67203	UCS/JUMPER/6IN/STD	6" Jumper
67204	UCS/JUMPER/24IN/STD	24" Jumper
67205	UCS/JUMPER/36IN/STD	36" Jumper

### DESCRIPTION AND OTHER OPTIONS

UCFL		/	60IN		/	120V		/	25W		/	30K		/	FR		/	WH		/	STD	
Family		Length		Voltage (VAC)		Wattage		Colour Temperature (K)		Lens Finish		Housing Colour Finish		Brand								
UCFL	Undercabinet FLUO LED	12IN	12 inches	120V	120 Volts	5W	5 Watts	30K	3 000 K	FR	Frosted	WH	White	STD	STANDARD							
		24IN	24 inches			10W	10 Watts									40K	4 000 K					
		36IN	36 inches			15W	15 Watts															
		48IN	48 inches			20W	20 Watts															
		60IN	60 inches			25W	25 Watts															

Qty	Description	Price

I accept the specifications of the luminaire configuration mentioned above.

Name: \_\_\_\_\_  
 Company: \_\_\_\_\_  
 Signature: \_\_\_\_\_

Date: \_\_\_\_\_

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice. August 8, 2019