

Eaton definite purpose contactor

C25BNB230A

UPC:786685116020

Dimensions:

- **Height:** 3.19 IN
- **Length:** 2.32 IN
- **Width:** 1.97 IN

Weight:.6 LB

Warranties:

- 1 year


Specifications:

- **Connection:** Quick
- **Amperage Rating:** 30A
- **Coil:** 110-120 Vac, 50/60 Hz
- **Enclosure:** Open with metal mounting plate
- **Frame Size:** Compact, two-pole
- **Model:** Contactor
- **Number Of Poles:** Two-pole
- **Resistive Load:** 40A
- **Terminals:** Binding head screw and quick connect terminals (side-by-side)
- **Type:** Non-reversing

Supporting documents:

- [Eatons Volume 5-Motor Control and Protection](#)
- [C25BNB AutoCAD 2D Footprint](#)
- [C25BNB AutoCAD 2D Footprint \(mm\)](#)
- [C25BNB 2D PDF](#)
- [C25BNB 2D Drawing Xchange](#)
- [C25BNB 3D Inventor](#)
- [C25BNB 3D Model Xchange](#)
- [Quick Selector - Definite Purpose Contactors](#)
- [Eaton Specification Sheet - C25BNB230A](#)

Certifications:

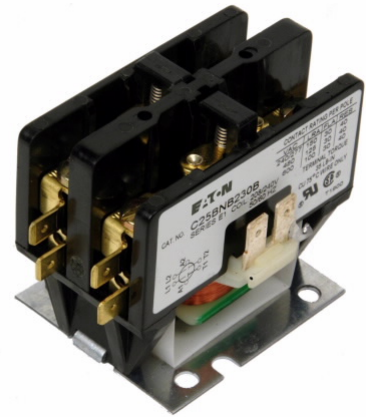

- UL Recognized
- CSA Certified

Product compliance:

- RoHS Compliant

© 2016 Eaton. All rights reserved.