


ORDERING INFORMATION

Order code: 63026
 Description: E254T5HOPS347/N/XTRM
 UPC: 69549630260

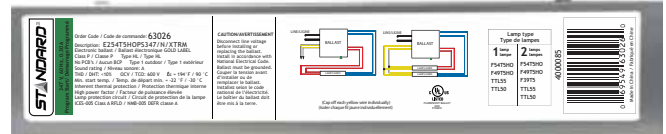

SPECIFICATIONS

Ballast type: Electronic
Starting method: Program Start
Lamp connection: Series
Input voltage (V): 347
Input frequency (Hz): 60
Max. case temperature: 90 °C
Thermal protection: Class P

Hazardous location: Type HL
Contains PCBs: No
Sound rating: A
Open current voltage (OCV) (V): 600
Inherent thermal protection: Yes
Lamp protection circuit: Yes
RFLD: ICES-005 Class A




347 VOLTS

Lamp type	Number of lamps	Rated lamp watts	Min. start temp. (°F / °C)	Input current (A)	Input power (ANSI watts)	Ballast factor	Max THD %	Power factor	Max. lamp current crest factor	B.E.F.
F54T5HO	2	54	-22/-30	0.33	116	0.99	10	0.99	1.7	0.85
F54T5HO	1	54	-22/-30	0.17	60	0.98	15	0.98	1.7	1.63
F54T5HO (49 W)	2	49	-22/-30	0.31	107	0.99	15	0.98	1.7	0.93
F54T5HO (49 W)	1	49	-22/-30	0.16	56	0.98	20	0.97	1.7	1.75
F54T5HO (47 W)	2	47	-22/-30	0.31	105	0.99	15	0.98	1.7	0.94
F54T5HO (47 W)	1	47	-22/-30	0.16	54	0.98	20	0.97	1.7	1.81
55W TTL	2	55	-22/-30	0.31	107	0.88	15	0.98	1.7	0.82
55W TTL	1	55	-22/-30	0.16	56	0.90	20	0.97	1.7	1.61
F39T5HO	2	39	-22/-30	0.26	92	0.98	15	0.98	1.7	1.07
50W TTL	2	50	-22/-30	0.32	112	1.04	15	0.98	1.7	0.93
50W TTL	1	50	-22/-30	0.17	58	1.06	20	0.97	1.7	1.83

ORDERING INFORMATION

Order code: 63026
 Description: E254T5HOPS347/N/XTRM
 UPC: 69549630260

WIRING DIAGRAM

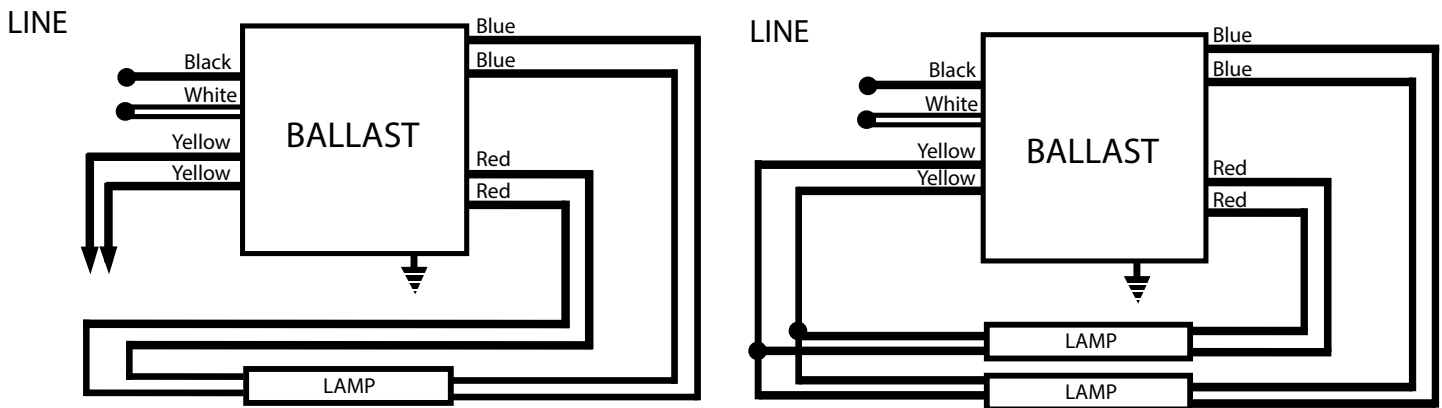

LEADS LENGTH

Black	18.8" (48 cm)
White	18.8" (48 cm)
Blue	30.9" (78.5 cm)
Red	30.9" (78.5 cm)
Yellow	46.4" (118 cm)

BALLAST DIMENSIONS

Length (L):	9.50" (24.1 cm)
Width (W):	1.70" (4.3 cm)
Height (H):	1.14" (2.9 cm)
Mounting (M):	8.90" (22.6 cm)

