

Individual Spec Sheet

SLA-1L / SLA-2L / SLA-3L / SLA12-2L

“EASY OUT” STEEL BATTERY UNIT

The commercial SLA-1L, SLA-2L, SLA-3L and SLA12-2L features a steel battery unit designed to provide efficient and reliable emergency lighting. Utilizing a sturdy all steel housing, our series presents a modern and unobtrusive design.

FEATURES AND SPECIFICATIONS

• Circuitry

- 120/347 VAC 60 Hz input, field selectable
- High efficiency, rapid recovery, precision control charging system
- 6 VDC 27 W and 36 W or 12 VDC 72 W emergency power output versions (as specified)
- Momentary push button test switch
- Diagnostic/pilot LED for AC ON and CHARGE
- Fully automatic, current limited charger
- Line latched, low voltage protection
- Solid state design and construction
- Brownout and short circuit protection
- Temperature compensated
- Complete battery recharge in 24 hours
- Maintenance free, sealed lead acid batter

• Mechanical

- 120 VAC line cord supplied standard
- Universal spider knockout pattern and keyhole mounting slots stamped into back of cabinet
- Multiple conduit entry knockouts
- White powder coat finish standard
- PAR18 small style, high impact thermoplastic heads
- LED heads with limited lifetime warranty¹

• Compliances

- CSA Certified to C22.2 #141-15



OVERVIEW

| | |
|----------|--|
| SLA-1L | <ul style="list-style-type: none"> – 6 VDC 27 W Battery capacity – Over 3 hours duration standalone unit – 2 x 2 W Crisp white LED heads |
| SLA-2L | <ul style="list-style-type: none"> – 6 VDC 36 W Battery Capacity – Over 4 hours Duration Standalone Unit – 2 x 2 W Crisp White LED Heads |
| SLA-3L | <ul style="list-style-type: none"> – 6 VDC 36 W Battery capacity – Over 3 hours duration standalone unit – 2 x 3 W Crisp white LED heads |
| SLA12-2L | <ul style="list-style-type: none"> – 12 VDC 72 W Battery Capacity – Over 8 hours Duration Standalone Unit – 2 x 2.5 W Crisp White LED Heads |



quick
ship



LED
fixture



ICES
005



¹ For complete warranty details, please see our terms and conditions in our website.

QUICK SHIP AND TECHNICAL SPECIFICATION TABLE 🕒¹

| Part number | DC Volts | Watts | Nbr of heads | Head | Lamp | Light source | Input Volts | Color |
|-------------|----------|-------|--------------|------|------|--------------|-------------|-------|
| | (VDC) | (W) | | | | | | |
| SLA-1L | 6 | 27 | 2 | N | 2 | LED | 120/347 | White |
| SLA-2L | 6 | 36 | 2 | N | 2 | LED | 120/347 | White |
| SLA-3L | 6 | 36 | 2 | N | 3 | LED | 120/347 | White |
| SLA12-2L | 12 | 72 | 2 | N | 2.5 | LED | 120/347 | White |

¹ **QUICK SHIP:** Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.


MODEL RATINGS

| Model | Volts (V) | Wattage capacities (W) | | | |
|----------|-----------|------------------------|---------|---------|----------|
| | | 30 min. | 60 min. | 90 min. | 120 min. |
| SLA-1L | 6 | 27 | 14 | 9 | 7 |
| SLA-2L | 6 | 36 | 18 | 12 | 9 |
| SLA-3L | 6 | 36 | 18 | 12 | 9 |
| SLA12-2L | 12 | 72 | 36 | 24 | 18 |

WIREGUARD

| Part number | Dimensions (in) |
|-------------|----------------------|
| WGD590 | 15.25 x 14.25 x 6.75 |

DIMENSIONS

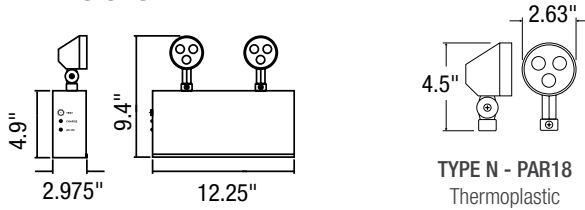

SPACING GUIDE

| Mounting height | Spacing center to center (ft) | | |
|-----------------|-------------------------------|-------|-----|
| | 2 W | 2.5 W | 3 W |
| 8 ft | 26 | 41 | 78 |
| 10 ft | 24 | 37 | 75 |
| 15 ft | 17 | 38 | 66 |
| 20 ft | 10 | 21 | 53 |

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions. All products are subject to change or may be discontinued any time without notice.