



Catalog Number
Notes
Type

Contractor Select™

FMML 13 FMML 7

Versi Lite™ LED Flush Mount



Available in 7" and 13" round, the LED Versi Lite Flush Mount offers an energy-efficient lighting solution for an array of indoor and outdoor residential and light commercial spaces. With a 50,000 hour maintenance-free life, the Versi Lite delivers reliability along with bright, high quality illumination. Ideal for use in closets, foyers, hallways, bedrooms, offices, utility work areas, stairways, and many other rooms in the house.

FEATURES:

- Available in 2 color temperatures; 3000K and 4000K
- Dimmable to 10% on most standard triac dimmers
- Wet location option



Catalog Number	UPC	Description	Replaces up to	Lumens	Input Watts	CCT	CRI	Voltage	Pallet qty.
FMML 13 840	888791432954	13" Versi Lite	2-75W Incandescent	2,000	28W	4000K	80	120V	120
FMML 7 830 M6	820476182860	7" Versi Lite	60W Incandescent	642	10W	3000K	80	120V	540
FMML 7 840 M6	753573647355	7" Versi Lite	60W Incandescent	642	10W	4000K	80	120V	540
FMML 7 840 WL M6	820476881145	7" Versi Lite*	60W Incandescent	642	10W	4000K	80	120V	540

More configurations are available. [Click here](#) or visit www.acuitybrands.com and search for FMML 13 & FMML 7

NOTES

*Wet Location.



Specifications

INTENDED USE:

Provides general illumination in commercial and residential applications. Ideal for use in closets, foyers, hallways, corridors, bedrooms, offices, utility work areas, outdoor covered areas, stairways and much more. Suitable for use within closet storage spaces when installed per NEC requirements.

CONSTRUCTION:

This contemporary shaped fixture features a matte white acrylic diffuser on the round versions, a polycarbonate diffuser on the square versions, and a robust aluminum housing. Wet location models are equipped with protective gasketing.

OPTICS:

Produces the following lumens at 50,000 hours life (WH finish):

3000 K: 642 lumens (7")/1898 lumens (13")

4000 K: 660 lumens (7")/1985 lumens (13")

ELECTRICAL:

Fixture operates at 120 volts, 60 Hz. 7" Round standard input = 9.3 watts, 70 lumens per watt. 13" Round standard input = 28 watts, 71 lumens per watt. 7".

Works with most standard incandescent dimmers

LISTINGS:

All sizes are CSA certified for sale in the USA and Canada. Also certified for Damp Location. For wet Location, the WL OPTION must be added to model number. ENERGY STAR® certified. Round Versi U.S. Patent No. D691,763

WARRANTY:

5-year limited warranty. Complete warranty terms located at:

www.acuitybrands.com/support/customer-support/terms-and-conditions

Note: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25 °C.

Specifications subject to change without notice.

 
Dimensions

7"

Height: 1-3/4 (4.4)

Width: 7-1/4 (18.4)

Weight: 1.1lbs (.5 kg)




13"

Height: 2-1/2 (6.4)

Width: 13 (33.0)

Weight: 3.2lbs

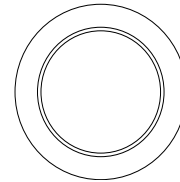

All dimensions are inches (centimeters) unless otherwise indicated.