


**Catalog No. 1SBV001106R1823**

Description: IPM2G Foot Switch

UPC No 3471522009050

Home &gt; Electronic Relays &amp; Controls &gt; Limit Switches

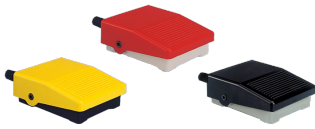

Representative Image

**Descriptors**

Category	Limit Switches
----------	----------------

**Specifications**

Product Main Type	Foot Switches
Number of Auxiliary Contacts NC	1
Number of Auxiliary Contacts NO	1
Action Type of the Contact Element (acc. to IEC 60947-5-1)	snap action contacts
Ambient Air Temperature	Operation -10 ... +70 °C Storage -25 ... +80 °C
RoHS Status	Following EU Directive 2011/65/EU
Actuation Torque	acc. to IEC 60947-5-1 Min. 1.2 N-m

**Dimensions**

Product Net Width	75 mm
Product Net Height	35 mm
Product Net Depth / Length	101 mm
Product Net Weight	0.101 kg

**Package Information**

Package Level 1 Units	1 piece
Package Level 1 Width	79 mm
Package Level 1 Height	38 mm
Package Level 1 Depth / Length	106 mm
Package Level 1 Gross Weight	0.121 kg
Package Level 1 EAN	3471522009050
Package Level 2 Units	1 piece
Package Level 2 Gross Weight	0.13 kg

**Ordering**

## Ordering

Minimum Order Quantity	1
Customs Tariff Number	85364900
Base Color	Grey