

## Eaton definite purpose contactor

### C25BNB240T

UPC:786685116105

#### Dimensions:

- **Height:** 3.19 IN
- **Length:** 2.32 IN
- **Width:** 1.97 IN

**Weight:** .6 LB

#### Warranties:

- 1 year


#### Specifications:

- **Connection:** Quick
- **Amperage Rating:** 40A
- **Coil:** 24 Vac, 50/60 Hz
- **Enclosure:** Open with metal mounting plate
- **Frame Size:** Compact, two-pole
- **Model:** Contactor
- **Number Of Poles:** Two-pole
- **Resistive Load:** 50A
- **Terminals:** Binding head screw and quick connect terminals (side-by-side)
- **Type:** Non-reversing

#### Supporting documents:

- [Eatons Volume 5-Motor Control and Protection](#)
- [C25BNB 2D Drawing Xchange](#)
- [C25BNB 3D Model Xchange](#)
- [C25BNB 2D PDF](#)
- [C25BNB AutoCAD 2D Footprint \(mm\)](#)
- [C25BNB AutoCAD 2D Footprint](#)
- [C25BNB 3D Inventor](#)
- [Eaton Specification Sheet - C25BNB240T](#)
- [Quick Selector - Definite Purpose Contactors](#)

#### Certifications:

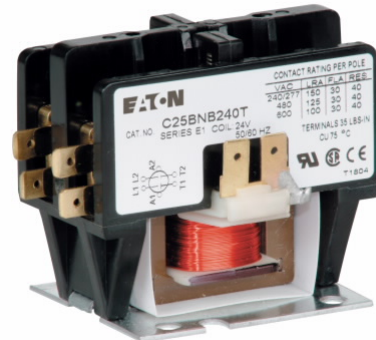

- CSA Certified
- UL Recognized

**Product compliance:**

- RoHS Compliant

---

© 2016 Eaton. All rights reserved.