




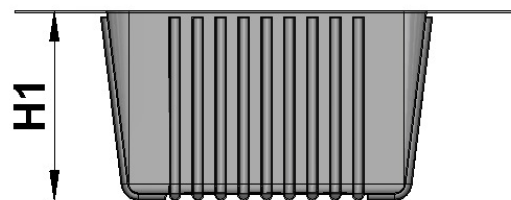

Granta Manufacturing

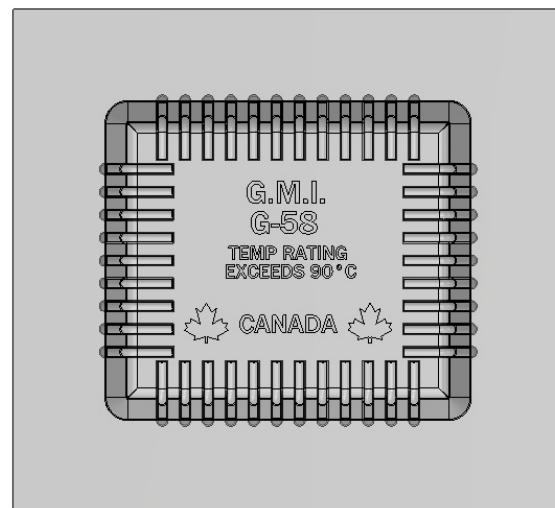

Vapor Barriers

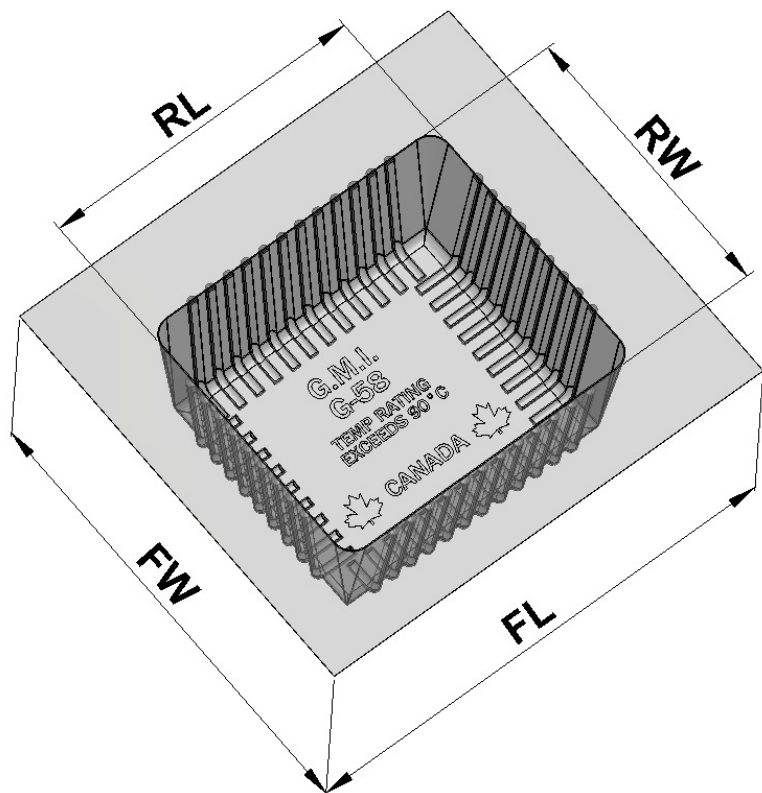

Description:

- Rib-reinforced vapor barrier box, finished with flange.
- FL / FW = Flange Length / Width, RL / RW = Recess Length / Width, H1 = Overall Height

Available Models / Dimensions:

G-41: Large Vapor Barrier (For bathroom fans or small pot lights, **no ribs**)

- FL = 24" FW = 20" RL = 11.5" RW = 9.25" H1 = 6.125"

G-58: Large Vapor Barrier (For bathroom fans or pot lights up to 6")

- FL = 24" FW = 22.5" RL = 16" RW = 14" H1 = 8"

G-59: X-Large Vapor Barrier (For all sizes of pot lights, compare with Contrast, Liteline, and Cool blue vapor barriers)

- FL = 29" FW = 22.75" RL = 22.25" RW = 14" H1 = 8.75"

G60: X-Large Vapor Barrier (Same design as G-59, **no ribs**)

- FL = 29" FW = 22.75" RL = 22.25" RW = 14" H1 = 8.75"

IW1624: X-Large Vapor Barrier (Same design as G-59, **no ribs**)

- FL = 29" FW = 22.5" RL = 22.25" RW = 14" H1 = 3.5"