



SDC Series



100 AMP - MULTI POSITION 200 Amp Mains c/w Blank Compartment

CATALOGUE #	TYPE	DESCRIPTION	DIMENSIONS (IN.)			WEIGHT
			H	W	D	
SDC220PW	O/H & U/G	2 gang, c/w blank compartment on left side	12	22 ¹ / ₂	5	24 lbs.
SDC320PW	O/H & U/G	3 gang, c/w blank compartment on left side	12	30	5	32 lbs.
SDC420PW	O/H & U/G	4 gang, c/w blank compartment on left side	12	37 ¹ / ₂	5	40 lbs.
SDC520PW	O/H & U/G	5 gang, c/w blank compartment on left side	12	45	5	47 lbs.
SDC620PW	O/H & U/G	6 gang, c/w blank compartment on left side	12	52	5	56 lbs.


- Factory Bussed - 200 Amp mains
- 2 - 6 position horizontal
- 4 Jaw meter sockets
- 100 Amp - 600 VOLTS per position
- Approved conductor range:
Line No. 6-250 MCM CU/AL
Load No. 6-1/0 AWG CU/AL
- Approved for overhead or underground use

- Field adaptable accessories
- 5th Jaw at 9 O'clock - **SXK503**
- For overhead order **SXC** hub separate
- Add suffix "RH" for right hand entry
- Add suffix "BC" for c/w 1 - 3" KO in the bottom

KNOCKOUT CODE	CONDUIT SIZE
D	1 ¹ / ₄ ", 1 ¹ / ₂ ", 2"
F	1, 1 ¹ / ₄ ", 1 ¹ / ₂ ", 2", 2 ¹ / ₂ ", 3"
AA	1 ¹ / ₂ "

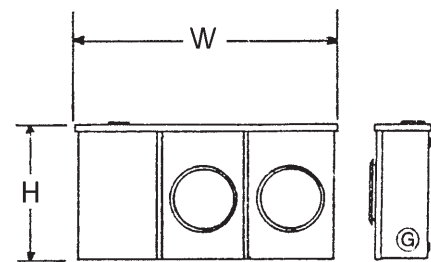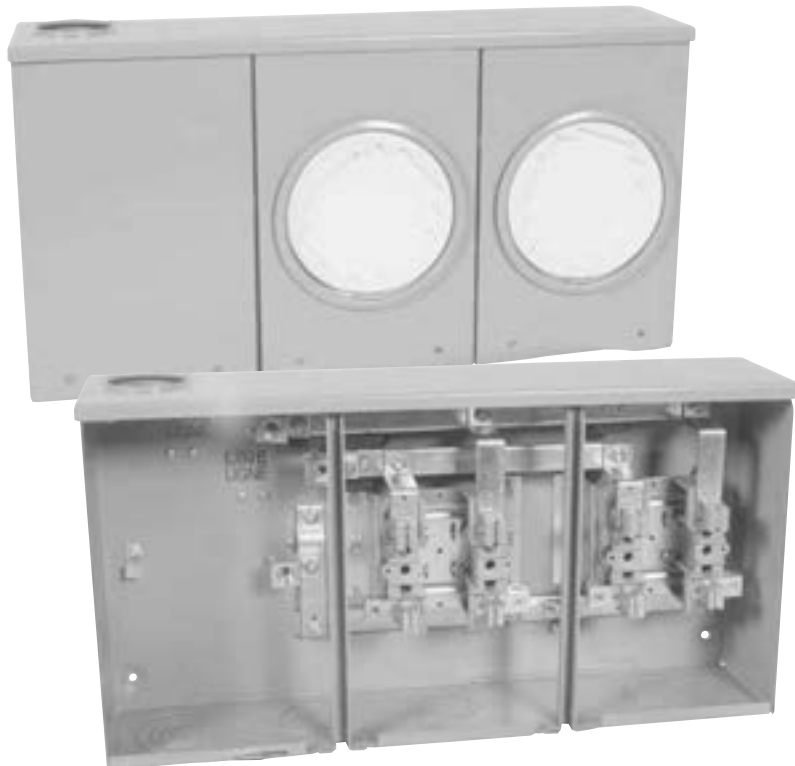

Extra Wiring Compartment

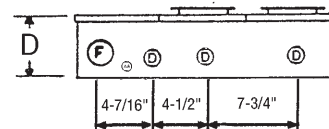

MCC Series



METER
SOCKETS



100 AMP - MULTI POSITION 200 Amp Mains, Compression Studs 1/2"

CATALOGUE #	TYPE	DESCRIPTION	DIMENSIONS (IN.)			WEIGHT
			H	W	D	
MCC220TW	U/G	2 gang, c/w blank compartment on left side	12	22 ¹ / ₂	5	24 lbs.
MCC320TW	U/G	3 gang, c/w blank compartment on left side	12	30	5	32 lbs.
MCC420TW	U/G	4 gang, c/w blank compartment on left side	12	37 ¹ / ₂	5	40 lbs.
MCC520TW	U/G	5 gang, c/w blank compartment on left side	12	45	5	47 lbs.
MCC620TW	U/G	6 gang, c/w blank compartment on left side	12	52	5	56 lbs.


- CSA enclosure 3R
- 1/2" Studs on line side
- Conductor range load size No. 6-1/0 AWG
- Compression studs on line side
- For underground use only
- Prebussed from main lugs to each position

- Add suffix "-R" for right hand entry
- Add suffix "-S" for used in Saskatchewan

KNOCKOUT CODE	CONDUIT SIZE
D	1 ¹ / ₄ ", 1 ¹ / ₂ ", 2"
F	1, 1 ¹ / ₄ ", 1 ¹ / ₂ ", 2", 2 ¹ / ₂ ", 3"
AA	1/2"

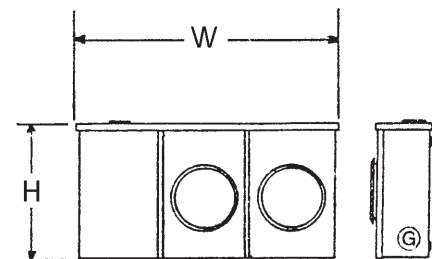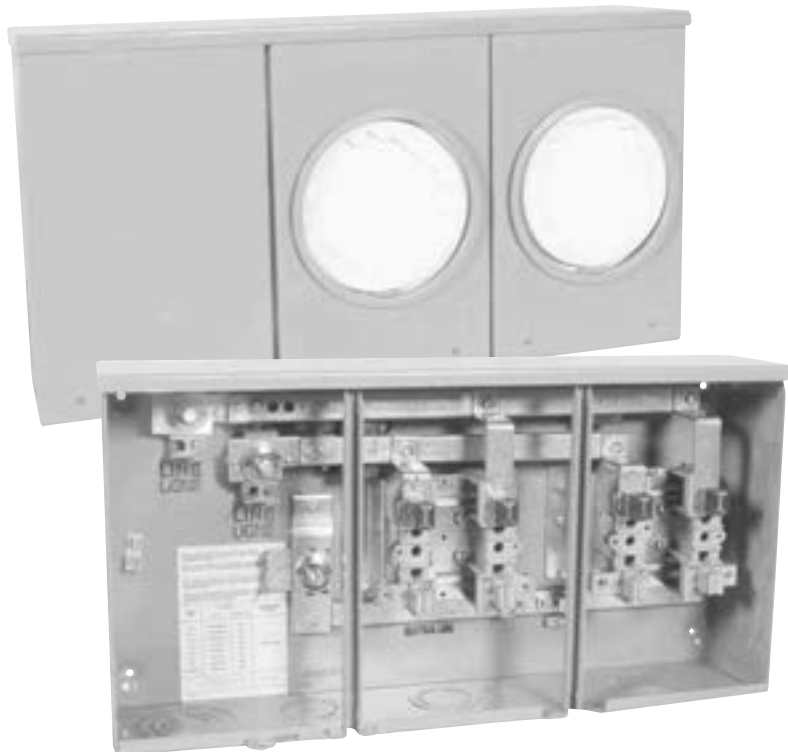

Extra Wiring Compartment

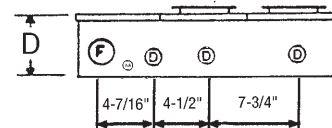




SLC Series

200 AMP - 600 VOLTS Lay in Lugs

CATALOGUE #	TYPE	DESCRIPTION	DIMENSIONS (IN.)			WEIGHT
			H	W	D	
SLC400RW	O/H & U/G	200 A with lay-in lugs	18	12	4 ³ / ₄	17 lbs.
SLC420RW	O/H & U/G	200 A c/w water heater lugs	18	12	4 ³ / ₄	17 lbs.
SLC400RWBC	O/H & U/G	200 A with lay-in lugs for British Columbia	18	12	5 ¹ / ₈	17 lbs.
SLC402RW	O/H & U/G	200 A with twin 1/0-14 lugs on load side Also approved by BC Hydro.	18	12	5 ¹ / ₈	17 lbs.

- CSA enclosure 3R
- Conductor range No. 6-250 MCM CU/AL
- Lay in type connectors makes wiring quick and easy
- 4 Jaw

KNOCKOUT CODE	CONDUIT SIZE
AA	1/2"
G	1 ¹ / ₄ ", 1 ¹ / ₂ ", 2", 2 ¹ / ₂ "
F	1", 1 ¹ / ₄ ", 1 ¹ / ₂ ", 2", 2 ¹ / ₂ ", 3"

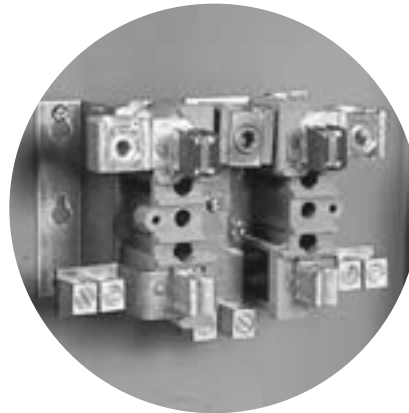

SLC402RW

