

AimLite


VPL4-L VAPOR TIGHT

NEMA 4X, NSF, IP66, 3 CCT



FEATURES

- 4' LED vapor tight comes standard with stainless steel latches
- Lightweight, slim and durable polycarbonate housing making the luminaire highly impact resistant
- Polycarbonate frosted lens
- 3 CCT select (35K, 40K, 50K)
- NEMA 4X and NSF certified
- 120-277 V or 120-347 V
- Ambient temperature: -40 °C to +40 °C

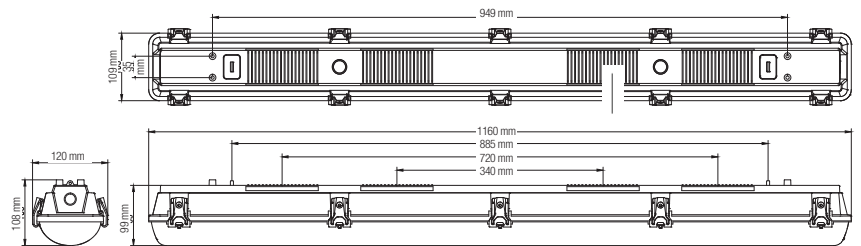

PART NUMBER	WATTS (W)	VOLTS (VAC)	COLOR TEMP. (K)	LUMEN OUTPUT (LM)	PALLET QUANTITY (PCS)
VPL4-LA3-2/3C	42	120-277	3 CCT (35K, 40K, 50K)	5 450	80
VPL4-LA4-2/3C	67	120-277	3 CCT (35K, 40K, 50K)	8 560	80
VPL4-LA3-32/3C	42	120-347	3 CCT (35K, 40K, 50K)	5 450	80
VPL4-LA4-32/3C	65	120-347	3 CCT (35K, 40K, 50K)	8 550	80