

LTR-P-WP Professional Series - Wet Location 24VDC 1.5W / 3.0W LED Tape Factory Configured Spec Sheet

PROJECT	TYPE
CATALOG NUMBER (FOR CUSTOM LENGTHS, PLEASE SEE ORDERING EXAMPLE BELOW)	

PRODUCT OVERVIEW

GM's Professional Wet Location Series Flexible LED Tape combines style and technology with reliability for outdoor applications. Designed for professional installations that demand a high level of quality, the LTR-P-WP Series includes a wide array of key features and is available in customizable runs in 2" increments (by factory). Do not submerge in water.

KEY FEATURES

- 24VDC
- 2400K, 2700K, 3000K, 3500K, 4000K and 5000K color temps
- Wet location
- 120 LEDs per meter
- Cuttable every 2"
- Optical clear UV protected silicone sheath
- Premium 2835 diodes
- 120° viewing angle
- Dimmable
- Maximum run on a given lead is 60' (1.5W) and 32'-8" (3.0W)
- Custom length configured at the factory

ELECTRICAL

- 24V
- 1.5 and 3.0 watts per foot

OPTICS


- 90+ CRI

CERTIFICATION

- UL
- Complies with Title 24 when used with Lutron HiLume Series
- Class 2

WARRANTY

- 5 year warranty when paired with GM power supply.

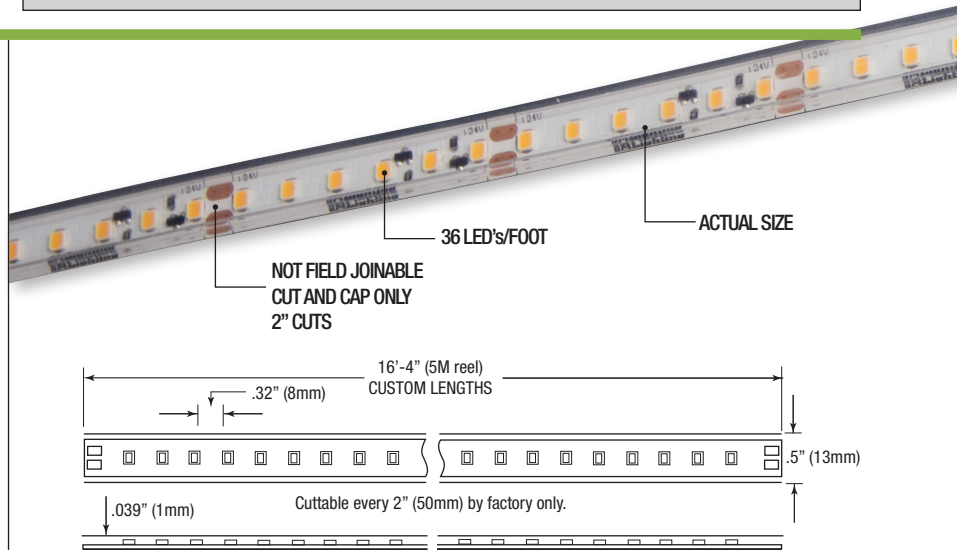

LTR-P SERIES ORDERING EXAMPLE

LTR-P - WP - 24V - X.XW - XXK - XX-X"

SERIES PREFIX (P = PRO)	LOCATION (WP = OUTDOOR)	VOLTAGE 24V	WATTS / FOOT 1.5W 3.0W	COLOR TEMP 24K = 2400K 27K = 2700K 30K = 3000K 35K = 3500K 40K = 4000K 50K = 5000K	CUSTOM CUT FEET-INCHES (CUTS MADE IN 2" INCREMENTS)
----------------------------	----------------------------	----------------	------------------------------	--	--

NOTE: NOT FIELD JOINABLE. CUT AND CAP ONLY. PLEASE
DOWNLOAD CUSTOM CONFIGURATOR FOR THIS PRODUCT ON
WEBSITE: www.gmlighting.net
DO NOT EXCEED MAXIMUM RUN.

PRODUCT ORDERING

Product No.	Length	Lumens per ft.	CRI	Color Temp.	Max. Run
LTR-P-WP-24V-1.5W-24K-FT	CUSTOM	102	90+	2400K	60'
LTR-P-WP-24V-1.5W-27K-FT	LENGTH: CONFIGURE	109	90+	2700K	60'
LTR-P-WP-24V-1.5W-30K-FT	ON WEBSITE	121	90+	3000K	60'
LTR-P-WP-24V-1.5W-35K-FT	DO NOT EXCEED MAX	121	90+	3500K	60'
LTR-P-WP-24V-1.5W-40K-FT	RUN	136	90+	4000K	60'
LTR-P-WP-24V-1.5W-50K-FT		144	90+	5000K	60'
LTR-P-WP-24V-3.0W-24K-FT	CUSTOM	210	90+	2400K	32'-8"
LTR-P-WP-24V-3.0W-27K-FT	LENGTH: CONFIGURE	225	90+	2700K	32'-8"
LTR-P-WP-24V-3.0W-30K-FT	ON WEBSITE	242	90+	3000K	32'-8"
LTR-P-WP-24V-3.0W-35K-FT	DO NOT EXCEED MAX	246	90+	3500K	32'-8"
LTR-P-WP-24V-3.0W-40K-FT	RUN	254	90+	4000K	32'-8"
LTR-P-WP-24V-3.0W-50K-FT		265	90+	5000K	32'-8"

Includes (1) TPC-12 tape to power connector, (20) silicon mounting clips and screws, (2) silicon end caps.
Kelvin temperature (color) ±100K.

For aluminum mounting channels or power supplies - see our website at www.gmlighting.net



CONNECTORS

Catalog No.	Description
TPC-12	Tape to power supply wet location connector
TTC-3	3" tape to tape wet location connector
TTC-6	6" tape to tape wet location connector
TTC-12	12" tape to tape wet location connector
TTC-24	24" tape to tape wet connector

DO NOT SUBMERGE DIRECTLY IN WATER.
WE RECOMMEND A 25% TO 80% LOAD FOR OPTIMAL
PERFORMANCE. SEE WEBSITE FOR COMPLETE LIST OF POWER
SUPPLIES AND COMPATIBLE DIMMERS.