

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1301460082](#)  
**Status:** **Active**  
**Overview:** [Watertite Wet-Location Wiring Solutions](#)  
**Description:** Watertite Extreme Plug with Locking Blade, 2 Pole/3 Wire, NEMA L5-15, 125V, Cord Grip Body Size F2, Silicone Husk

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR6837  
 UL E10176

**General**

Product Family Wiring Devices  
 Series [130146](#)  
 IP Rating IP69K  
 NEMA Configuration NEMA L5-15  
 Overview [Watertite Wet-Location Wiring Solutions](#)  
 Product Name Watertite Extreme  
 Receptacle Type N/A  
 Specialty N/A  
 Type Plug  
 UPC 78678871202

**Physical**

Cord Grip Body Size F2 1/2"  
 Flange No  
 Flip Lid No  
 Gender Male  
 Length N/A  
 Locking Blade Yes  
 Net Weight 126.552/g  
 Poles 2-pole/3-wire

**Electrical**


Cord Type N/A  
 Current - Maximum per Contact 15.0A  
 GFCI No  
 Lighted Connector No  
 Voltage - Maximum 125V

**Material Info**

Engineering Number 24W47

**Reference - Drawing Numbers**

Sales Drawing 1301460082-000

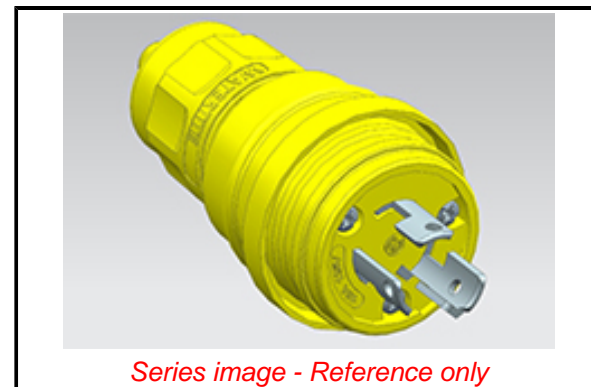

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[130146 Series](#)