



Catalog Number
Notes
Type

Contractor Select™


# RLNK

## LED Linkable Strip Light

This LED strip light is capable of linking with additional fixtures while providing smooth end-to-end illumination. Ideal choice for garages, under/over cabinet, storage closets and displays.

**FEATURES:**

- Compact-designed channel formed from steel with white paint finish
- Diffuse polycarbonate lens standard
- Surface mounts individually to the ceiling or wall

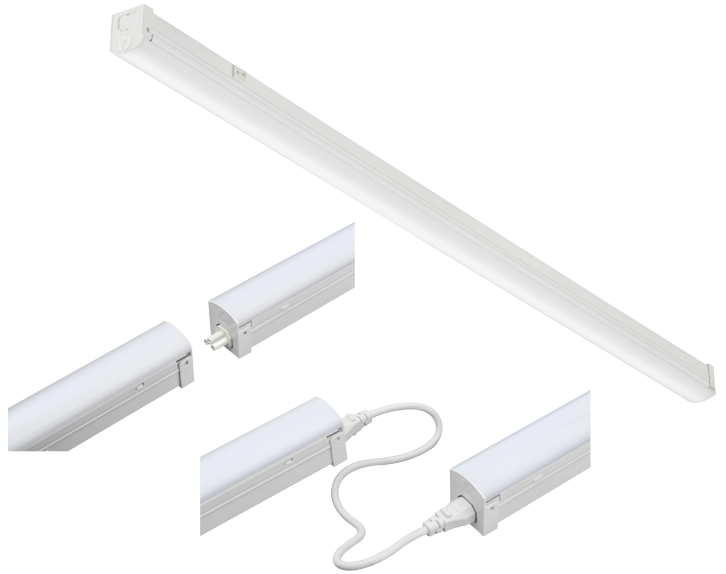

† Portable Luminaire Certified in the California Title 20 Modernized Appliance Efficiency Database (MAEDBS)

Catalog Number	UPC	Description	Lumens	Wattage	Voltage	Color Temperature	Color Rendering Index	Pallet Quantity
RLNK L24 120 35K 80CRI M4	00194994373230	2ft Linkable LED Strip Light	940	8.9	120	3500K	80CRI	240
RLNK L48 120 35K 80CRI M4	00194994373308	4ft Linkable LED Strip Light	1950	19.7	120	3500K	80CRI	200



## Specifications

### INTENDED USE:

This LED strip light is capable of linking with additional fixtures while providing smooth end-to-end illumination. Ideal choice for garages, under/over cabinet, storage closets and displays. Certain airborne contaminants can diminish integrity of acrylic and/or polycarbonate. [Click here for Acrylic-Polycarbonate Compatibility table for suitable uses.](#)

### CONSTRUCTION:

Compact-designed channel formed from steel with white paint finish. End caps made from injection molded 5VA polycarbonate. On/off rocker switch accessible from the side of the fixture.

### OPTICS:

LEDs provide 80+ color rendering index (CRI) at 3500K. Diffuse polycarbonate lens standard. L70 > 54,000 hours expected life.

### ELECTRICAL:

Luminaire Surge Protection Level: Designed to withstand up to 2.5kV/0.75kA per ANSI C82.77-5-2015. For applications requiring higher level of protection, additional surge protection must be provided. Fixture features a non-dimming driver operating at 120V.

### INSTALLATION:

May be installed as direct wire or as a portable luminaire with use of 5ft power cord (included). Surface mounts individually to the ceiling or wall. May be installed either horizontally or vertically. Capable of linking together up to 18 units utilizing either the row connector or 18" linking cord (included).

### LISTINGS:

UL certified to US and Canadian safety standards. For use in damp locations with minimum starting temperature of 0°F - 95°F (-18°C - 35°C). ENERGY STAR® certified.

### WARRANTY:

5-year limited warranty. Complete warranty terms located at: [www.acuitybrands.com/support/warranty/terms-and-conditions](http://www.acuitybrands.com/support/warranty/terms-and-conditions)

**Note:** Actual performance may differ as a result of end-user environment and application. All values are design or typical values, measured under laboratory conditions at 25 °C. Specifications subject to change without notice.

## Dimensions

Model	Length	Depth	Height	Weight
RLNK L24	22.8	1.58	1.82	2.0 lbs
RLNK L48	46.43	1.82	3.3 lbs	

All dimensions are inches (centimeters) unless otherwise indicated.

