

STRING LIGHT

Our String Lights were designed to provide temporary lighting in tough environments, whether you need lighting for a wide area or to perform a specific task. They are offered in lengths of 50' (15 m) and 100' (30 m) and are made of 12 or 14 AWG cable, which allows for them to be daisy-chained.

FEATURES AND SPECIFICATIONS

- **Construction**

- Color: Yellow
- Lamp guard material: Plastic

- **Wire specifications**

- 50' (15 m): SJTW 12 AWG / 3C
- 100' (30 m): SJTW 14 AWG / 3C
- NEMA 5-15

- **Technical specifications**

- Heavy duty E26 sockets handle up to 150 W
- Daisy-chain capability
- Suitable for use in dry locations

- **Ambient temperature**

- 40°C to +60°C

- **Compliances**

- ETL



QUICK SHIP AND TECHNICAL SPECIFICATION TABLE 🕒¹

Order code	Part number	Wire Length ft. (m)	Wire	Maximum Watts per Socket (W)	Volts		Amperage (A)	Socket	Number of Sockets	Lamp Guard Material	Case qty (master)
					(Sockets)	(String)					
66850	SL/50FT/DSC/5SKT/12AWG/PLASTIC/YL/STD	50 (15)	SJTW 12 AWG / 3C	150	120	125	12	E26	5	Plastic	1
67770	SL/100FT/DSC/10SKT/14AWG/PLASTIC/YL/STD	100 (30)	SJTW 14 AWG / 3C	150	120	125	12	E26	10	Plastic	1

¹ **QUICK SHIP:** Product availability is subject to change without notice. Please contact your Stanpro customer service representative to confirm inventory levels at time of order.

ACCESSORIES (order separately)

Order code	Part number	Type	Case qty (master)
66853	SL/CAGE/PLASTIC/YL/STD	Plastic Cage Replacement	50
66854	SL/SHOOK/METAL/STD 5P	Metal S Hooks (Pack of 5)	100

REPLACEMENT PLASTIC CAGE




S HOOKS




DIMENSIONS

STRING LIGHTS (50')

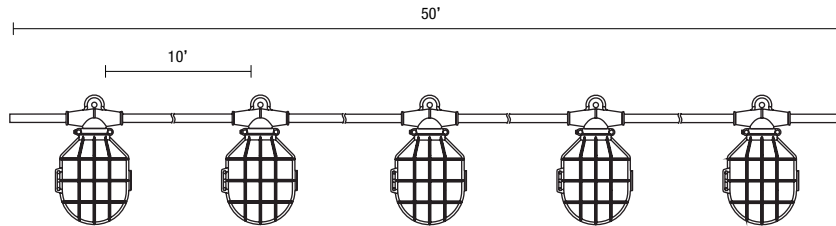

STRING LIGHTS (100')

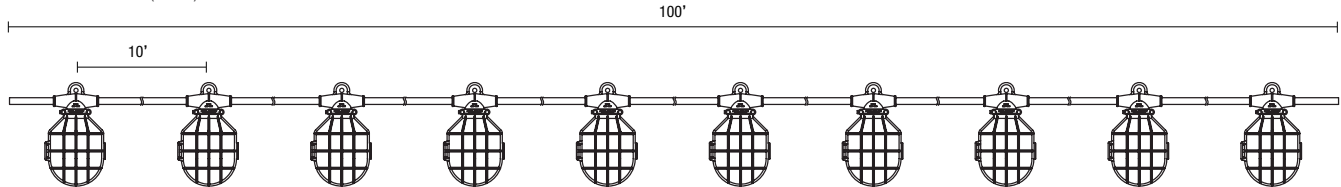

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions. All products are subject to change or may be discontinued any time without notice.