


**Alternate Catalog No. PSR12-600-70**  
**Catalog No. 1SFA896106R7000**

**Description: PSR SOFTSTARTER 11A CTRL 110-240V**

**UPC No 7320500338247**

**Home > Drives and Soft Starters > Softstarter - Open (PSR)**

**PSR softstarter - The compact range** The PSR softstarter range is a simple yet reliable starting solution that utilizes only the most basic of soft starting features: soft start and stop. It performs well in applications requiring many starts per hour and is perfect for installations where you need to save space. **Main benefits\*** Small and compact starting solution\* Can perform many starts per hour\* Reduce energy loss at full speed with built-in bypass. **Main features\*** Rated operational current: 3 to 105 A\* Operational voltage: 208-600 V AC\* Control supply voltage: 24 V AC/DC or 100-240 V AC.

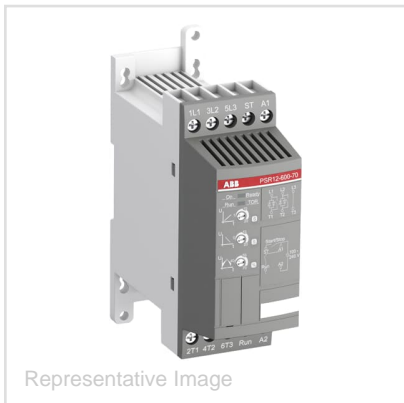

Representative Image

**Descriptors**

Category	Softstarter - Open (PSR)
----------	--------------------------

**Specifications**

Product Type	Soft Starters
Input Voltage	208-600 V
Control Voltage	100-240 V
Normal Duty: Output Current (A)	11
Normal Duty: Motor Power (HP) at 460V	7.5
Power Dissipation In Watts	11.5

**Classifications**

RoHS Indicator	Yes
UL/CUL Listing	Yes

**Dimensions**

Height (in)	5.5
Width (in)	1.8
Depth (in)	4.5
Weight (lb)	0.99
Height (mm)	140
Width (mm)	45
Depth (mm)	113.5
Weight (kg)	0.45