


Alternate Catalog No. PSR16-600-70
Catalog No. 1SFA896107R7000

Description: "PSR SOFTSTARTER 15,2A CRTL 110-240V"

UPC No 7320500338261

Home > Drives and Soft Starters > Softstarter - Open (PSR)

PSR softstarter - The compact range The PSR softstarter range is a simple yet reliable starting solution that utilizes only the most basic of soft starting features: soft start and stop. It performs well in applications requiring many starts per hour and is perfect for installations where you need to save space. **Main benefits*** Small and compact starting solution* Can perform many starts per hour* Reduce energy loss at full speed with built-in bypass. **Main features*** Rated operational current: 3 to 105 A* Operational voltage: 208-600 V AC* Control supply voltage: 24 V AC/DC or 100-240 V AC.

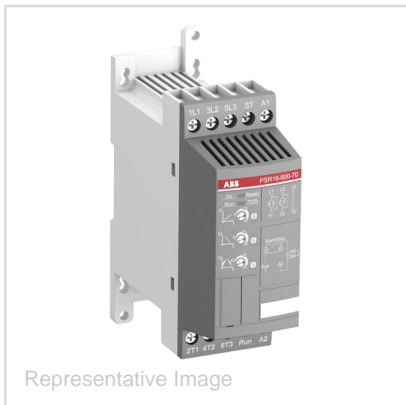

Descriptors

Category	Softstarter - Open (PSR)
----------	--------------------------

Specifications

Product Type	Soft Starters
Input Voltage	208-600 V
Control Voltage	100-240 V
Normal Duty: Output Current (A)	15.2
Normal Duty: Motor Power (HP) at 460V	10
Power Dissipation In Watts	20.5

Classifications

RoHS Indicator	Yes
UL/CUL Listing	Yes

Dimensions

Height (in)	5.5
Width (in)	1.8
Depth (in)	4.5
Weight (lb)	0.99
Height (mm)	140
Width (mm)	45
Depth (mm)	113.5
Weight (kg)	0.45