



# PL-T Triple 4-Pin Base

## PL-T 26W/827/A/4P/ALTO

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

### Warnings and Safety

• Lamp contains mercury. Manage in Accord with Disposal Laws. See: [www.lamprecycle.org](http://www.lamprecycle.org) or 1-800-555-0050

### Product data

General Information	
Base	GX24Q-3 [ GX24q-3]
LSF Preheat 2000 h Rated	99 %
LSF Preheat 4000 h Rated	98 %
LSF Preheat 6000 h Rated	97 %
LSF Preheat 8000 h Rated	90 %

Light Technical	
Color Code	827 [ CCT of 2700K]
Initial lumen (Nom)	1750 lm
Luminous Flux (Rated) (Nom)	1750 lm
Color Designation	Incandescent White
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	64.8 lm/W
Color Rendering Index (Nom)	82
LLMF 2000 h Rated	92 %

Operating and Electrical	
Power (Rated) (Nom)	27.0 W
Lamp Current (Nom)	0.335 A

Temperature	
Design Temperature (Nom)	28 °C

Controls and Dimming	
Dimmable	Yes

LLMF 4000 h Rated	88 %
LLMF 6000 h Rated	85 %
LLMF 8000 h Rated	84 %
LLMF 12000 h Rated	81 %

## PL-T Triple 4-Pin Base

### Mechanical and Housing

Cap-Base Information 4P

### Approval and Application

Energy Efficiency Label (EEL) B

Mercury (Hg) Content (Nom) 1.4 mg

### Product Data

Order product name PL-T 26W/827/A/4P/ALTO

EAN/UPC - Product 046677384401

Order code 458240

Numerator - Quantity Per Pack 1


Numerator - Packs per outer box 10

Material Nr. (12NC) 927910982750

Net Weight (Piece) 64.000 g

ILCOS Code FSM-26/27/1B-E-GX24q=3


### Dimensional drawing

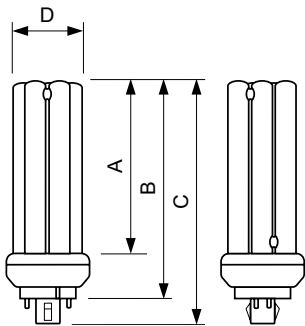


PL-T ALTO 26W/827/4P A

Product	D (max)	A (max)	B (max)	C (max)
PL-T 26W/827/A/4P/ALTO	41 mm	86.7 mm	111.0 mm	126.7 mm

### Photometric data

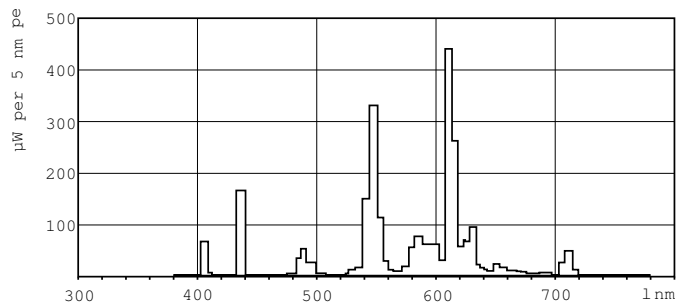


LDPB\_PLTTOP4P\_827-Spectral power distribution B/W

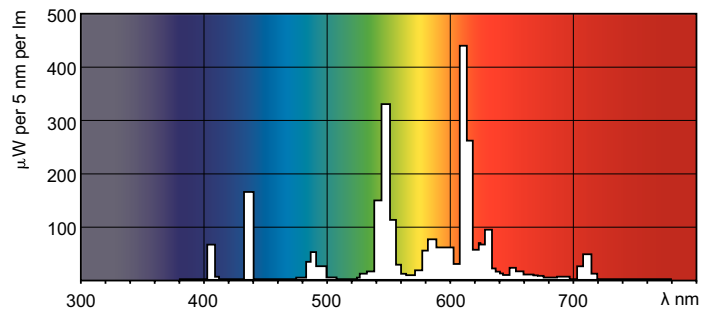

LDPO\_PLTTOP4P\_827-Spectral power distribution Colour


# PL-T Triple 4-Pin Base

## Lifetime

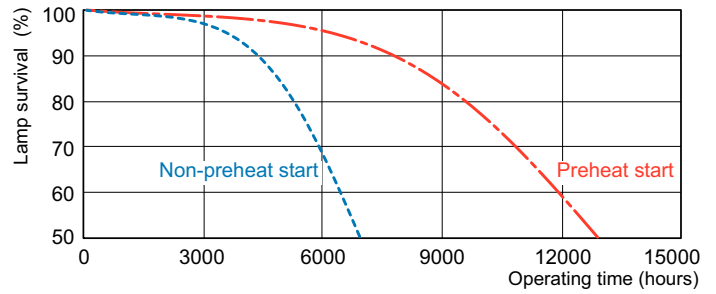

LDLM\_PLTTOP4P\_0001-Lumen maintenance diagram

LDLE\_PLTTOP4P\_0001-Life expectancy diagram

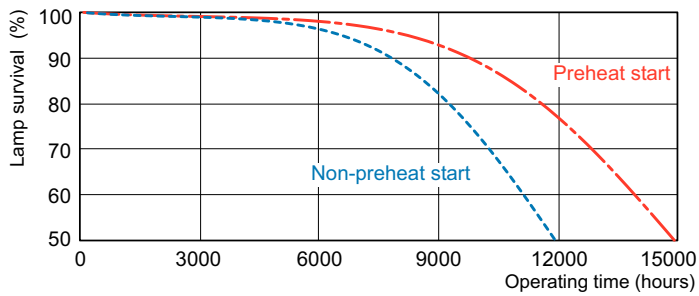

LDLE\_PLTTOP4P\_0002-Life expectancy diagram

