



ULTRA TUGGER® 10
and Mobile VersiBoom II



Mobile VersiBoom™ II and Ultra Tugger®

The Ultra Tugger and Mobile VersiBoom offer a flexible solution that can match almost any pull or job site situation and help get the job done quickly and easily.

The Ultra Tugger 10 (UT10-2S) has multiple mounting options; aside from using the Mobile VersiBoom™ II, you also have the option to use it with a floor mount or chain mount.

Two-Speed Ultra Tugger (UT10-2S)

The Ultra Tugger 10,000-pound puller has two speeds and can shift from high speed to low speed with a double-tap motion on the foot pedal. High speed can pull up to 16 feet per minute up to 4,000 pounds, while low speed can pull 8,000 pounds at 9 feet per minute. The capacity peaks at 10,000 pounds at a rate of 6 feet per minute.

Mobile VersiBoom II


The Mobile VersiBoom sets up in less than two minutes and can be used in almost every pulling situation. This combination of speed and versatility can increase the number pulls per day and help deliver greater benefit to your bottom line!

ULTRA TUGGER® 10

PRODUCT FEATURES

The UT10-2S motor is designed specifically for heavy-duty cable pulling applications. Greenlee's two-speed motor provides consistently stronger pulling power at less amperage than the competition. This increases durability and provides a steady pull speed.

- Two-speed motor allows for fast pulls up to 10,000 pounds
- The strong, rugged motor is designed to handle both large and small cable pulling applications up to 10,000 pounds
- On-board force gauge uses LED lights to display pulling force and speed
- Quickly change from high-speed to low-speed by double-tapping the foot pedal
- Removable foot pedal for storage

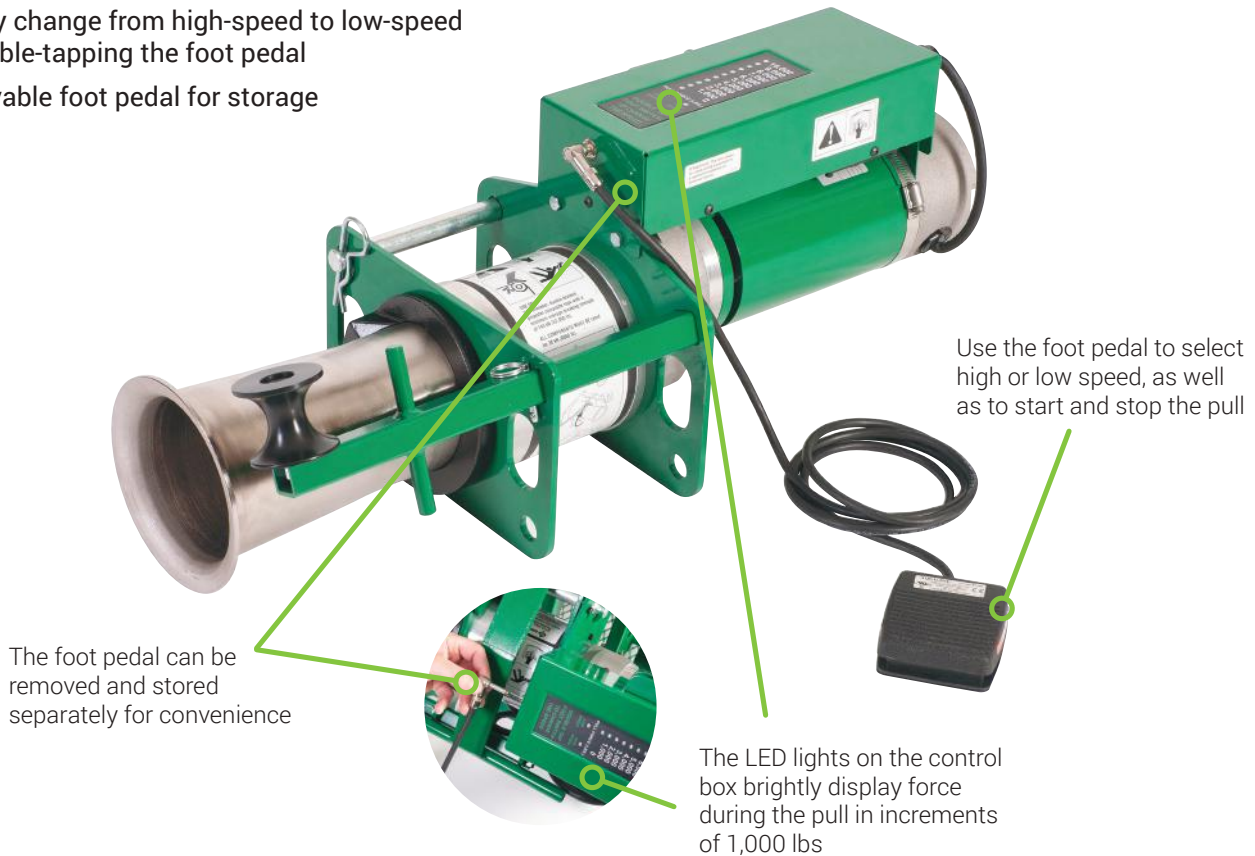

PULLING FORCE

0 lbs. to 6,500 lbs. (0 kN to 28.9 kN):

CONTINUOUS OPERATION

6,500 lbs. to 8,000 lbs. (28.9 kN to 35.6 kN):

15 MINUTES ON / 15 MINUTES OFF


8,000 lbs. to 10,000 lbs. (35.6 kN to 44.5 kN):

MOMENTARY

	HIGH SPEED	LOW SPEED
No Load:	16 FT/MIN (4.88 M/MIN)	—
2,000 lbs. (8,900 N):	14 ft/min (4.27 m/min)	—
4,000 lbs. (17.8 kN):	12 ft/min (3.66 m/min)	—
6,000 lbs. (26.7 kN):	—	7 ft/min (2.13 m/min)
8,000 lbs. (35.6 kN):	—	6 ft/min (1.83 m/min)

MOBILE VersiBoom® II

SIMPLE ONE PERSON SET-UP IN LESS THAN TWO MINUTES

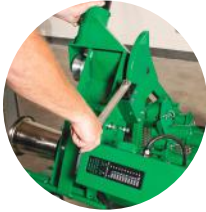

1 Lift the boom to desired angle using crank



2 Position the elbow to desired angle



3 Position the nose just over conduit and lower adapter into conduit by cranking the boom lower

Interchangeable Nose and Elbow





Built-in Storage
Store adapters for 2" - 5" conduit




Quick Clean Up

Folds down in under 2 minutes to be small enough to fit in a pickup truck

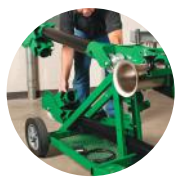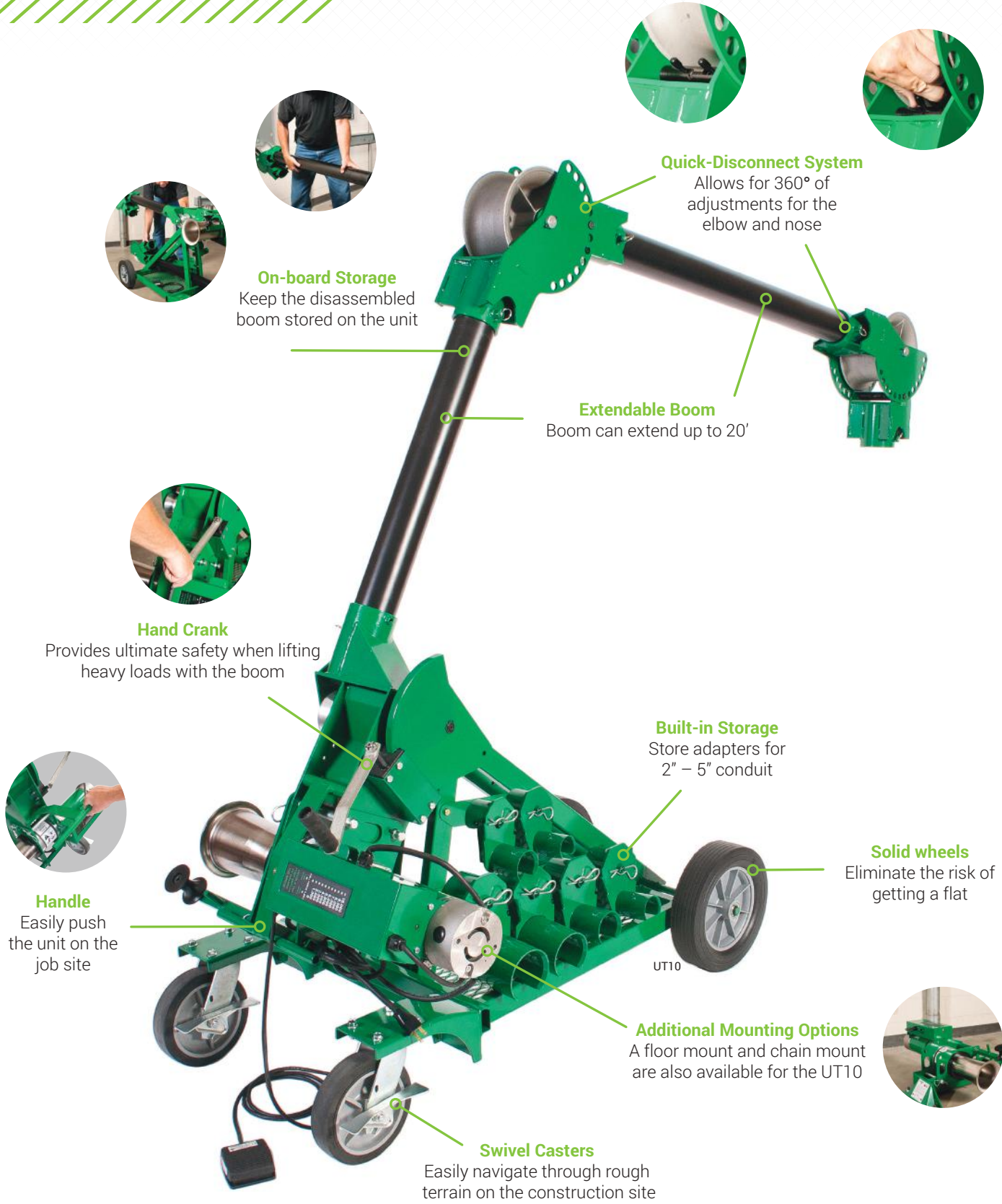

On-board Storage
Keep the disassembled boom stored on the unit

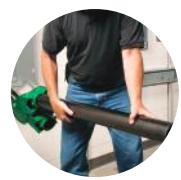

Quick-Disconnect System
Allows for 360° of adjustments for the elbow and nose



Extendable Boom
Boom can extend up to 20'



Hand Crank
Provides ultimate safety when lifting heavy loads with the boom



Handle
Easily push the unit on the job site

Built-in Storage
Store adapters for 2" – 5" conduit

Solid wheels
Eliminate the risk of getting a flat

Additional Mounting Options
A floor mount and chain mount are also available for the UT10



Swivel Casters
Easily navigate through rough terrain on the construction site

UT10

UT10 PRODUCTS



6906A

UT10-2S Package with Mobile VersiBoom II and 6 Adapters



6900

UT10-2S Package with Floor mount



6901

UT10-2S Package with Chain mount



Cable Feeder

Increase efficiency and productivity by using a cable feeding system to make cable setup and payout a one-person job.



G-Series Smart Pull

Monitor real time force, speed and distance during a cable pull avoiding rework and liability.



Rope

Use up to 7/8" rope with a maximum rated capacity that meets or exceeds the cable pullers maximum pulling force.



Cable Handling

A comprehensive line of jack stands, reel rollers, caddies and dispensers to efficiently handle cable payout.



Grips & Crimpers

Save time by using Gator Grips. Select the size for an indent crimper, and be set up for the pull in less than two minutes.

KIT SELECTION GUIDE

PRODUCTS INCLUDED

CAT. NO.	UPC NO.	DESCRIPTION	UT10 Kits				Mobile VersiBoom II Kits:	
			6900	6901	6906	6906A	MVB	MVB-A
UT10-2S	05528	Puller Assembly (UT10)	X	X	X	X		
02846	02846	Chain Mount Ass'y-Pkgd	X					
00865	00865	Mount Assy-Floor		X				
MVB	00553	Mobile VersiBoom II			X		X	
MVB-A	00610	Mobile VersiBoom II and 6 Adapters				X		X
00561	00561	3' Boom			X	X	X	X
00560	00560	4' boom			X	X	X	X
00563	00563	Adapter Weldment, 2"				X		X
00564	00564	2-1/2" Adapter			X	X	X	X
00565	00565	Adapter Weldment, 3"			X	X	X	X
00566	00566	Adapter Weldment, 3-1/2"				X		X
00567	00567	4" Adapter			X	X	X	X
00610	00610	Adapter Weldment, 5"				X		X
00583	00583	Adapter Assembly, 2" Screw-On						
00584	00584	Adapter Assembly, 2-1/2" Screw-On						
00585	00585	Adapter Assembly, 3" Screw-On						
00586	00586	Adapter Assembly, 3-1/2" Screw-On						
00587	00587	Adapter Assembly, 4" Screw-On						

KIT OPTIONS

ORDERING INFORMATION

	CAT NO.	UPC NO.	DESCRIPTION
NEW	6906A	00567	UT10-2S Package with Mobile VersiBoom II and 6 Adapters
	6906	00359	UT10-2S Package with Mobile VersiBoom II
	6906-22	00812	UT10-22 (220 V) Package with Mobile VersiBoom II
	6900	00357	UT10-2S Package with Floor mount
	6900-22	00814	UT10-22 (220 V) Package with Floor mount
	6901	00358	UT10-2S Package with Chain mount
	6901-22	00813	UT10-22 (220 V) Package with Chain mount
	UT10-2S	05528	Puller Assembly
	UT10-22	00829	(220 V) Puller Assembly
NEW	MVB-A	00610	Mobile VersiBoom II and 6 Adapters
	MVB	00553	Mobile VersiBoom II
	00471	00471	Coupling Hanger Kit
	00563	00563	Adapter Weldment, 2"
	00564	00564	Adapter Weldment, 2-1/2"
	00565	00565	Adapter Weldment, 3"
	00566	00566	Adapter Weldment, 3-1/2"
	00567	00567	Adapter Weldment, 4"
	00610	00610	Adapter Weldment, 5"
	00583	00583	Adapter Assembly, 2" Screw-On
	00584	00584	Adapter Assembly, 2-1/2" Screw-On
	00585	00585	Adapter Assembly, 3" Screw-On
	00586	00586	Adapter Assembly, 3-1/2" Screw-On
	00587	00587	Adapter Assembly, 4" Screw-On
	00588	00588	Hanger Weldment, Short
	00589	00589	Hanger Weldment, Long
	00590	00590	Screw On Coupling Kit



MA5676 REV 10/18
4455 Boeing Dr • Rockford, IL 61109 • USA • 800-435-0786
©2018 Greenlee Tools, Inc. • An ISO 9001 Company • Printed in USA
GREENLEE.COM



Professional. Nothing Less.™

