



A-Shape LED

14A19/LED/850/FR/P/ND 4/2FB

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.


Product data

General Information		Power Factor (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5
EU RoHS compliant	Yes	Voltage (Nom)	120 V
Nominal Lifetime (Nom)	11000 h	Temperature	
Switching Cycle	50000X	T-Case Maximum (Nom)	95 °C
Technical Type	14-100W	Controls and Dimming	
Light Technical		Dimmable	No
Color Code	850 [CCT of 5000K]	Mechanical and Housing	
Luminous Flux (Nom)	1500 lm	Bulb Finish	Frosted
Color Designation	Daylight [Daylight]	Approval and Application	
Correlated Color Temperature (Nom)	5000 K	Energy Efficiency Label (EEL)	Not applicable
Luminous Efficacy (rated) (Nom)	107.00 lm/W	Energy Consumption kWh/1000 h	14 kWh
Color Consistency	<6	Product Data	
Color Rendering Index (Nom)	80	Order product name	14A19/LED/850/FR/P/ND 4/2FB
LLMF At End Of Nominal Lifetime (Nom)	70 %	EAN/UPC - Product	50046677462012
Operating and Electrical		Order code	462010
Input Frequency	60 Hz	Local order code	.
Power (Rated) (Nom)	14 W	Numerator - Quantity Per Pack	1
Lamp Current (Nom)	255 mA	Numerator - Packs per outer box	4
Wattage Equivalent	100 W	Material Nr. (12NC)	929002311815
Starting Time (Nom)	0.5 s		
Warm Up Time to 60% Light (Nom)	0.5 s		

A-Shape LED

Net Weight (Piece) 0.040 kg



Dimensional drawing

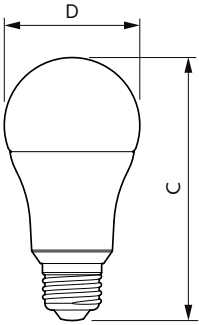

Bulb A60 15-100W 1500lm 5000K E26 ND

Product	D	C
14A19/LED/850/FR/P/ND 4/2FB	60 mm	117 mm


Photometric data

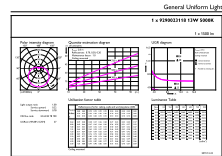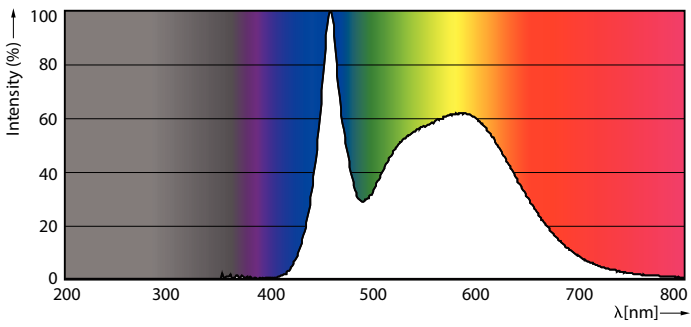

Copyright © 2019 Philips Lighting B.V. Page 17

LEDbulb 14W E26 A9 850 FR



LEDbulb 14W E26 A9 850 FR

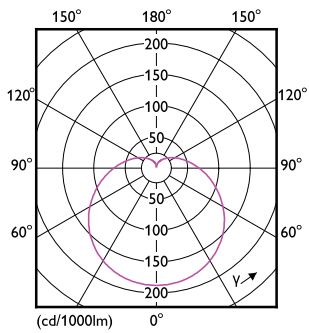

LEDbulb E26 A9 FR 1

A-Shape LED

Lifetime

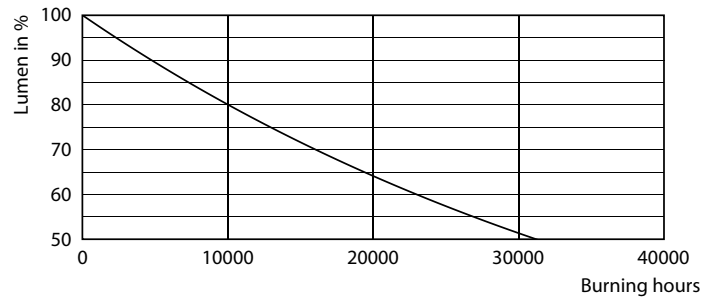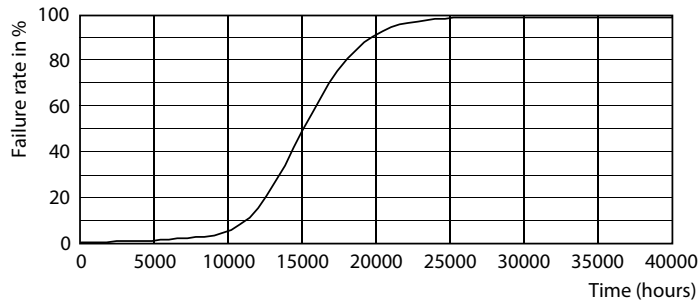

15K LED

15K LMP

