

# Power Hook for Industrial High Bay Luminaires

## Furnished with Receptacle, Plug, 18" 16-3 SO Cord and Loop Fixture Hanger

**CEC:**  
Listed for Ordinary (Unclassified) Locations

### Applications

- Designed for suspension of lighting fixtures.

### Features

- G-HBPH power hook for industrial luminaires
  - Loop that suspends fixture cannot be removed until plug is disconnected from power receptacle.
  - 20 Amp plug, receptacle and cable are provided in all voltages.
  - Rotating plug after insertion locks plug in receptacle, eliminating plug fall-out.
  - Loop and hook provide flexible mounting, ideal in areas where vibration is encountered.
- Three 3/4" openings - one on top and one on each side.
- Furnished with two close up plugs.

### Standard Materials

- Copperfree (4/10 of 1% max.) cast aluminum


### Standard Finishes

- Powder coat epoxy

### CEC Certifications and Compliances

- CSA Standard: C22.2 No. 9, C22.2 No. 250
- CSA Certified: 009349

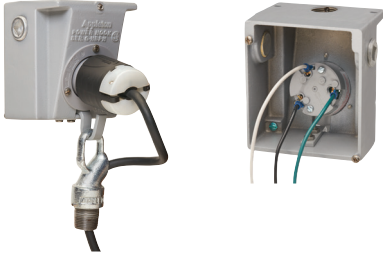

		Size (Inches)	Voltage	Catalog Number
		3/4	120	G-HBPH-120
		3/4	208	G-HBPH-208
		3/4	240	G-HBPH-240
		3/4	277	G-HBPH-277
		3/4	347	G-HBPH-347
		3/4	480	G-HBPH-480
		3/4	600	G-HBPH-600

POLES/HANGERS: NEC/CEC ORDINARY LOCATION FLEXIBLE FIXTURE HANGERS

