




TYPE PQ

FEMALE FINGRIP™

THREE PIECE VINYL-INSULATED

MATERIAL: BRASS

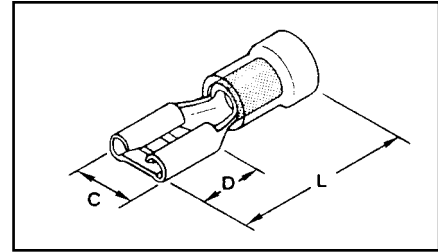

An inner copper sleeve provides wire support against vibration and flexing.



MATES WITH .250 X .032 NEMA TAB

CATALOG NUMBER	LOOSE PIECES						TAPE MOUNTED		WIRE STRIP LENGTH	
	WIRE RANGE	MATERIAL AND FINISH	DIMENSIONS			BULK CATALOG NO.	HAND TOOL	CATALOG NO. 2000/Reel		TFM CRIMP DIE
			D	L MAX	C					
PQ18R257D	22-18 MAX. INSUL. DIA.: .135"	Brass	.30	.85	.30	PQ18R257B	MR8-92* Y10D Y10-22	PQ18R257M	DFM13D1	9/32"
PQ18R258D	SLEEVE COLOR: RED	Tin plated brass				PQ18R258B		PQ18R258M		
PQ14R257D	16-14 MAX. INSUL. DIA.: .160"	Brass	.30	.85	.30	PQ14R257B		PQ14R257M	DFM12D1	
PQ14R258D	SLEEVE COLOR: BLUE	Tin plated brass				PQ14R258B		PQ14R258M		
PQ10R258D	12-10 MAX. INSUL. DIA.: .250" SLEEVE COLOR: YELLOW	Tin plated brass	.30	1.00	.30	PQ10R258B	MR10D* Y10-22 Y10D	PQ10R258M	DFM16D1	3/8"

Recognized under the Component Program of Underwriter's Laboratories, Inc.
*PQ10 -- M Wound 1,000/Reel

MATES WITH .187 X .020 NEMA TAB

CATALOG NUMBER	LOOSE PIECE						TAPE MOUNTED		WIRE STRIP LENGTH	
	WIRE RANGE	MATERIAL AND FINISH	DIMENSIONS			BULK CATALOG NO.	HAND TOOL	CATALOG NO. 2000/Reel		TFM CRIMP DIE
			D	L MAX	C					
PQ18R187D	22-18 MAX. INSUL. DIA.: .135"	Brass	.25	.76	.23	PQ18R187B	MR8-92* Y10D Y10-22	PQ18R187M	DFM13D1	9/32"
PQ18R188D	SLEEVE COLOR: RED	Tin plated brass				PQ18R188B		PQ18R188M		
PQ14R187D	16-14 MAX. INSUL. DIA.: .160"	Brass				PQ14R187B		PQ14R187M	DFM121	
PQ14R188D	SLEEVE COLOR: BLUE	Tin plated brass				PQ14R188B		PQ14R188M		

Recognized under the Component Program of Underwriter's Laboratories, Inc.
* UL Recognized when installed with MR8-92 or MR10D & MR10D2 Tools Only.