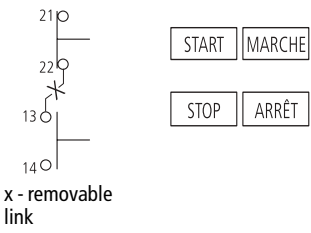
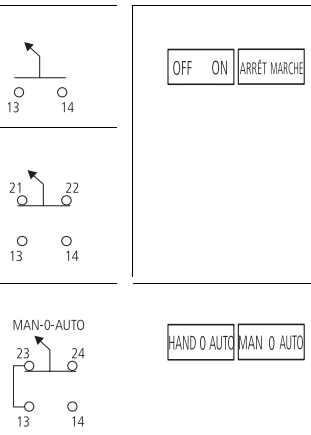
 
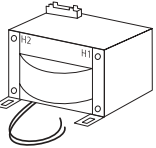


## Magnetic Contactors and Starters

### Field Modification Kits

Symbols and Legend Plates		Description	English version	French version	List Price see price list
English / French text			Type Article No.	Type Article No.	
<b>Double pushbutton</b> 		Double pushbutton mounting in single hole  Double pushbutton mounting in single hole c/w LED element 85-264 V AC operating range	<b>DDL/K11-CS</b> 110315  <b>DDL/K11/230-R-CS</b> 110317	<b>DDL/K11-CS-F</b> 110316  <b>DDL/K11/230-R-CS-F</b> 110318	
<b>Selector switches</b> 		2 position selector switch with legend plate  3 position selector switch with legend plate	<b>WKV/K10-CS</b> 110319  <b>WKV/K11-CS</b> 110321  <b>WRK3/K20-CS</b> 110323	<b>WKV/K10-CS-F</b> 110320  <b>WKV/K11-CS-F</b> 110322  <b>WRK3/K20-CS-F</b> 110324	
<b>Pilot light</b> 		Red pilot light, c/w LED element 85 - 264 V AC operating range	<b>L-R/230-R-CS</b> 110325		

	VA Rating VA	Secondary fuse A	Contactor Size	T...-600/120	List Price	T...-480/120	List Price
				Type		Type	
<b>Control transformers <sup>1)</sup></b> including fuse block and fuse  	50	0.5	DILEM, DIL00(A)M, DIL0(A)M, DIL1(A)M	<b>T50-600/120</b> 101730		<b>T50-480/120</b> 101729	
	75	0.75	DIL2(A)M, DILM185, DILM225, DILM250, PKZ2(-SP)	<b>T75-600/120</b> 101736		<b>T75-480/120</b> 101735	
	100	1.0	DIL3M80, DILM300, DILM400, DILM500	<b>T100-600/120</b> 101722		<b>T100-480/120</b> 101721	
	150	1.5	DIL4M115	<b>T150-600/120</b> 101724		<b>T150-480/120</b> 101723	
	250	2.5	DILM580, DILM650, DILM750, DILM820	<b>T250-600/120</b> 101726		<b>T250-480/120</b> 101725	
	500	5.0		<b>T500-600/120</b> 101732		<b>T500-480/120</b> 101731	

Note:

<sup>1)</sup> The standard enclosure may or may not have room for the addition of a control transformer.