

MICRO SENSORS AND SWITCHES INLINE CHANNEL MOUNTED

DESCRIPTION

Four unique sensors that can work inline, remote, and/or be built into the channel itself.

FEATURES

- * Micro push button on/off only
- * Touch with dimming and memory
- * Proximity (swipe hand near sensor) on/off only
- * PIR timed 6-70s

CUSTOM PRE-INSTALLATION ASSEMBLY AVAILABLE UPON REQUEST

SPECIFICATIONS

Input Voltage: 24VDC
Loading Power: 8A Max

MEASUREMENTS

CRTB01 -- 17.1mm x 80mm
CRTT03 -- 17.1mm x 80mm
CRTSPIRIT -- 17.1mm x 100mm
CRTS01 -- 17.1mm x 85mm



CRTB01 -- Micro Button Switch

One touch on/off switch



CRTT03 -- Dimming Touch Switch

Blue light identifying where to touch to control
Hold to dim on/off



CRTSPIRIT -- PIR Motion Sensor

Adjustable timer controlling the length of time the lights stay on from 6 to 70 seconds



CRTS01 -- Proximity Hand Sensor

On/off function only
Swipe hand past sensor to activate

Project: _____

Type: _____

Date: _____

Part #: _____

DESCRIPTION

Three unique sensors offering solutions to a wide range of applications.

FEATURES

- * Flush circular dimmable touch switch with memory (offered in black and white)
- * Dimmable sub-surface switch capable of sensing touch through wood, composite, or glass surfaces up to 30mm thick
- * Interchangeable door/hand operated multi-sensor switch

SPECIFICATIONS

Input Voltage: 24VDC
Loading Power: 8A Max



CRTT04B / CRTT04W -- Dimming Touch Switch

Dimensions: 22mm diameter (Hole required is 18mm diameter)
Flush circular dimmable touch switch
Available in black and white

Pictures Coming
Soon!

CRTT006 -- Dimming Touch Surface Switch

Dimmable sub-surface switch capable of sensing touch through wood, composite, or glass surfaces up to 30mm thick



CRTSIRDH -- Door / Hand Sensor

Detection Range: ≤ 10 cm

Project: _____

Type: _____

Date: _____

Part #: _____

DLSMT-024V-(18W/36W) ELECTRONIC NON-DIMMABLE DRIVER

DESCRIPTION

Diffusion DLSMT-024V-(18W/36W) is an electronic, non-dimmable driver in a plastic enclosure.

FEATURES



- * No junction box required
- * 18W or 36W
- * IP40 Rating

RATED FOR INDOOR USE ONLY

SPECIFICATIONS

DLSMT-024V-18W
 Input: 120V
 Output: 24VDC
 Output Current: 0.75A
 Dimensions: 4.5" L x 1.75" W x 1.125" H

DLSMT-024V-36W
 Input: 120V
 Output: 24VDC
 Output Current: 1.5A
 Dimensions: 5.5" L x 1.75" W x 1.125" H

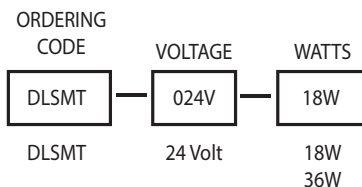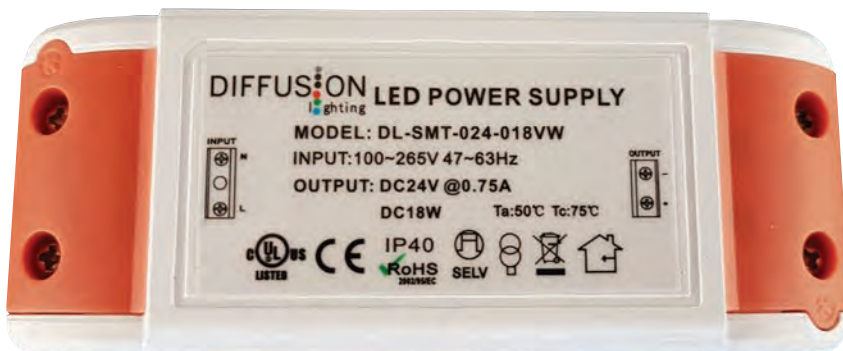

Project: _____

Type: _____

Date: _____

Part #: _____