


Features:

High power handling 6.5" in-ceiling speaker system
Trim-less magnetic grille
Smooth-wide frequency response
6.5 inch polypropylene woofer cone
Rubber woofer surround
20 oz Ferrite woofer magnet
1 inch aim-able silk dome tweeter
Neodymium tweeter magnet
High quality crossover with air core inductor
White acoustically lined grille .
4 heavy duty "Tough Cam" mounting clamps.
Gold plated 12awg binding posts
Complete rough in bracket included (RI-675)
Also available in 25/70 volt (E-675X-TL, X-TL20, X-TL30)
Sold as pairs
Master carton 2 pcs
10 year warranty

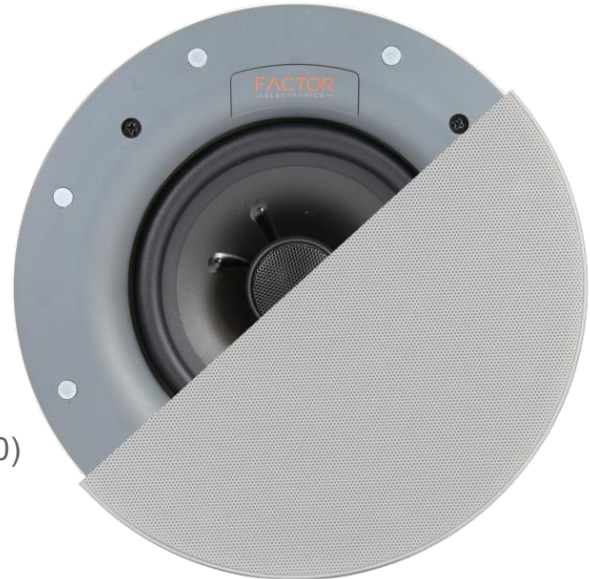

Specifications:

Diameter Woofer 6.5" (165.1mm) polypropylene
Diameter Tweeter 1" (25.4mm) silk dome aim-able
Power Handling 125 watts (peak)
Impedance 8 ohms (nominal)
Frequency Response 40Hz - 20kHz (± 10 dB)
Dispersion 110 °
Sensitivity 92dB (1W 1M) Average



Included:

RI-675 rough-in bracket
Cutout template
Paint shield

Dimensions:

Dimensions Overall 10.125" (250mm)
Cutout Dimensions Speaker 8.25" (210mm)
Cutout Dimensions RI Bracket 8.5" (216mm)
Depth 3.5" (90mm)
Shipping Weight 13lbs (5.9kg)
Shipping dimensions 14x12x13"

New "Tough-Cam" Mounting System

