



LED FIXTURE

SSL Series

LED Stringer Light Set SSL-STRINGER

24 Light, LED outdoor stringer light set




Features & Benefits


CUL listed, wet location approved	Includes 24 bulbs plus 2 spares
Decorative filament LED bulbs 2200K (warm light)	Shatter-resistant bulbs
14.6m / 48 ft heavy-duty 16/3 cord with male & female molded connectors	Bulbs spaced 2ft on centre
Connect up to 45 sets 658m / 2160ft using 1W LED lamp only	Energy saving 1 watt LED bulbs, 120V

Installation

1. If attaching to the guide wire, attach the ring at the back of the bulb holder to the guide wire using a S-hook or cable tie.

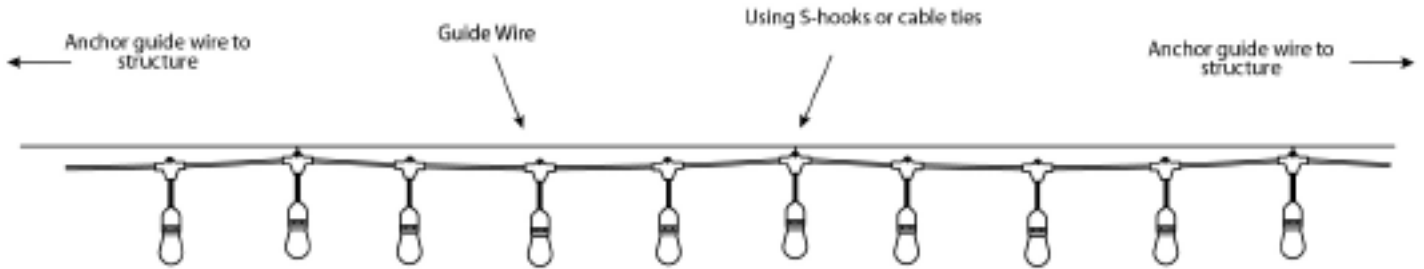

2. If a guide wire is not used, connect securely to structure at the beginning, middle and the end of EACH string light.

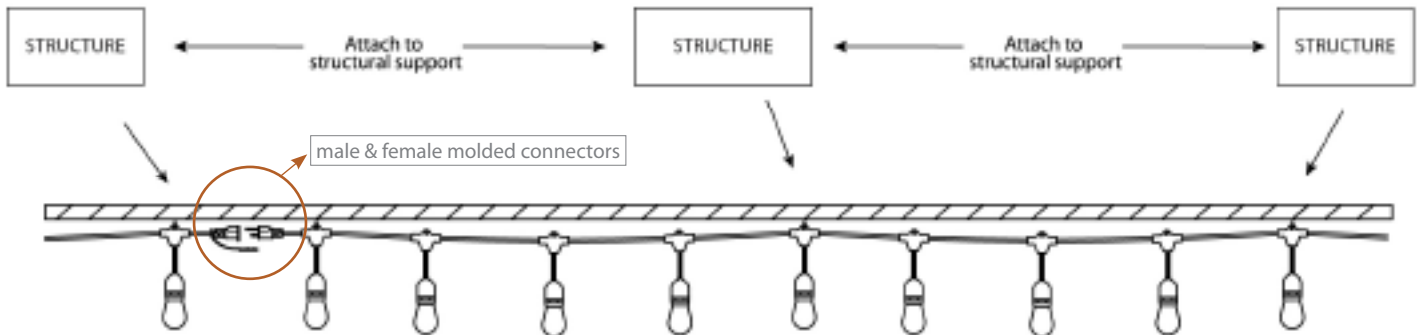

Ordering Information Example: SSL-STRINGER/48F/24W/22K/120V

Family Name	Fixture Type	Total Length	Wattage Per Set (Maximum)	CCT	Input Line Voltage
SSL (Solid State Lighting)	STRINGER (Stringer Light Set)	48F (48 feet)	24W	22K (2200K)	120V

Product Specification

Order Code	Model Number
3664118	SSL-STRINGER/48F/24W/22K/120V