

# Juno® Trac 12™ Linear Lighting



## Wedge Base

 
Wedge base lampholders are compatible with wedge base lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

### TL201


#### Lamp

One 12V or 24V, 10W max. T3-1/4 wedge base lamp

#### Dimensions



#### Finishes

 

Black (BL)




White (WH)

### TL202
 
#### Lamp

Two 12V or 24V, 10W max. T3-1/4 wedge base lamps

#### Dimensions



#### Finishes



Black (BL)



White (WH)

## Xenon T3-1/4 Wedge Base Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL900 CLR	12	3	Clear	15
TL901 CLR	12	5	Clear	33
TL903 CLR	12	10	Clear	83
TL905 FRST 24	24	5	Frosted	29
TL910 FRST 24	24	10	Frosted	91

## Rigid Loop

 
The rigid loop lampholder includes a stationary reflector to forward project more of the 360° light from the lamp. They are compatible with rigid loop style lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. Rigid loop lamps possess all of the advantages of the wedge base lamps, but offer a more symmetrical light distribution and slightly higher output that is optimal for cove lighting applications. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

### TL211

#### Lamp

One 12V or 24V, 10W max. T3-1/4 rigid loop lamp

#### Dimensions



#### Finishes



Black (BL)



White (WH)

## Xenon T3-1/4 Rigid Loop Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL950 CLR	12	5	Clear	45
TL950 FRST	12	5	Frosted	45
TL951 CLR	12	10	Clear	100
TL951 FRST	12	10	Frosted	100
TL952 CLR 24	24	5	Clear	40
TL952 FRST 24	24	5	Frosted	40
TL953 CLR 24	24	10	Clear	90
TL953 FRST 24	24	10	Frosted	90

## Festoon


The festoon lampholder includes an articulating reflector, enabling more precise aiming of the light. They are compatible with festoon type lamps that are 10W or less and T3-1/4 size or smaller including xenon, LED, etc. The festoon lamp is similar to the rigid loop lamp, though more widely available and offering slightly greater light output. Xenon lamps emit a white light that approximates the color of halogen, but have up to a 20,000-hour lamp life and do not require fixture lenses or special handling.

### TL212

#### Lamp

One 12V or 24V, 10W max. T3-1/4 festoon lamp

#### Dimensions

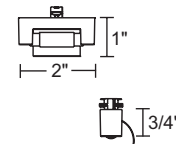

#### Finishes



Black (BL)



White (WH)

## Xenon T3-1/4 Festoon Lamps

Cat. No.	Volts	Watts	Clear/ Frosted	Rated Lumens
TL960 CLR	12	5	Clear	50
TL960 FRST	12	5	Frosted	50
TL961 CLR	12	10	Clear	120
TL961 FRST	12	10	Frosted	120
TL964 CLR 24	24	5	Clear	50
TL964 FRST 24	24	5	Frosted	50
TL965 CLR 24	24	10	Clear	120
TL965 FRST 24	24	10	Frosted	120



©2017 Acuity Brands Lighting, Inc. The marks appearing in this catalog are trademarks of Acuity Brands Lighting, Inc. Products shown in this brochure may be covered by U.S. and international patents and patents pending. Specifications subject to change without notice. Printed in the U.S.A.