

Wall Mounts

Rocelco MDS-LP Medium Low Profile Wall Mount




Low Profile - mounts screen 25 mm from wall - keeps your thin TV looking thin.

Designed for concrete/brick and stud walls.

Wall bracket designed for extra-secure double-stud mounting.

Includes security screw locking system and bubble level.

Easy 3-step installation, all mounting hardware included.

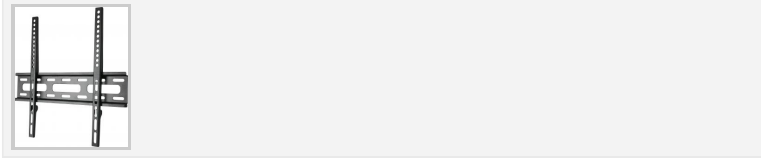

Specification

Model Number	MDS-LP	
UPC Number	6-93285-00012-6	
Product Name	Rocelco MDS-LP Medium Low Profile Wall Mount	Fits Screens
Product Brand	Rocelco	Minimum Diagonal Width: 23.00 inches
Category	Wall Mounts	Maximum Diagonal Width: 47.00 inches
Sub Category	Low Profile	Maximum Weight Capacity
		30.00kg / 66.00 lbs
		Tilting
		No
		Articulated (Y/N)
		No
		Cord Control
		No
		Distance from wall
		23.00 mm / 0.90 inches
		Bracket Dimension
		Width: 17.50"
		Height: 4.10"
		Fits Vesa Patterns
		200x100mm, 200x200mm, 300x300mm, 400x200mm, 400x300mm, 400x400mm

