



TrueForce High Lumen PAR

33PAR38/PER/830/S15/DIM/120V 6/1FB

Philips LED TrueForce PAR high lumen lamps are the perfect transition from CDM lamps to LED.

Product data


General Information		Lamp Current (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		300 mA
EU RoHS compliant	Yes	Wattage Equivalent	250 W
Nominal Lifetime (Nom)	25000 h	Starting Time (Nom)	0.5 s
Switching Cycle	50000X	Warm Up Time to 60% Light (Nom)	0.5 s
Technical Type	33-250W	Power Factor (Nom)	0.95
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	830 [CCT of 3000K]	T-Case Maximum (Nom)	90 °C
Beam Angle (Nom)	15 °		
Luminous Flux (Nom)	3000 lm	Controls and Dimming	
Luminous Intensity (Nom)	35000 cd	Dimmable	Yes
Color Designation	White (WH)		
Correlated Color Temperature (Nom)	3000 K	Approval and Application	
Luminous Efficacy (rated) (Nom)	90.00 lm/W	Energy Efficiency Label (EEL)	Not applicable
Color Consistency	<4	Suitable For Accent Lighting	Yes
Color Rendering Index (Nom)	80	Energy Consumption kWh/1000 h	- kWh
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and Electrical		Product Data	
Input Frequency	50 to 60 Hz	Order product name	33PAR38/PER/830/S15/DIM/120V 6/1FB
Power (Rated) (Nom)	33 W	EAN/UPC - Product	046677534608
		Order code	534602

TrueForce High Lumen PAR

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001916804

Net Weight (Piece)	0.425 kg
--------------------	----------


Dimensional drawing

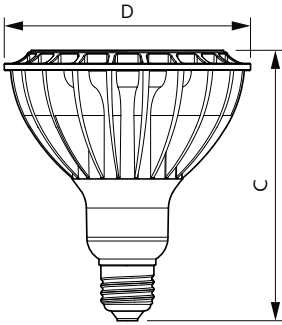


PAR38 120V 32-W 2800lm 15D 3000K E26 D

Product	D	C
33PAR38/PER/830/S15/DIM/120V 6/1FB	123 mm	133 mm


Photometric data

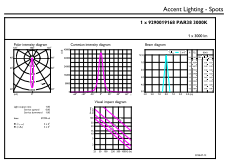

LEDSpot 33W E26 PAR38 S15

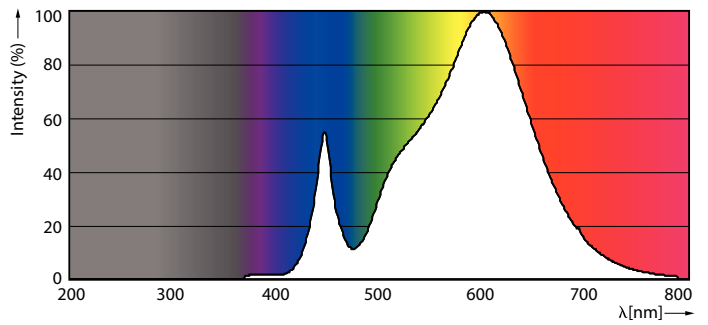


LEDSpot 33W E26 PAR38

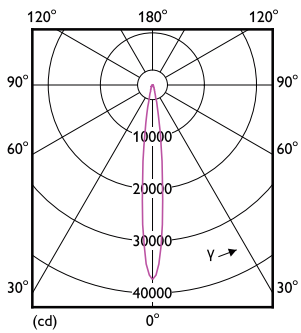


LEDSpot 33W E26 PAR38 S15

TrueForce High Lumen PAR

Lifetime

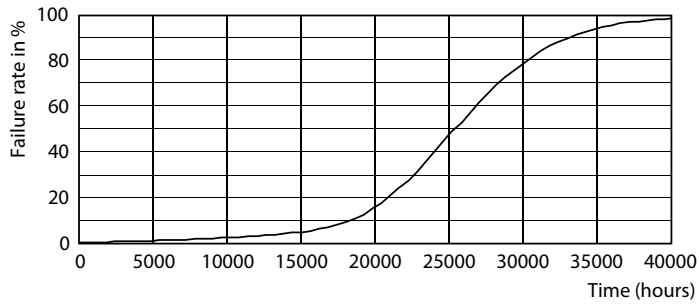

LEDSpot 33W E26 PAR38

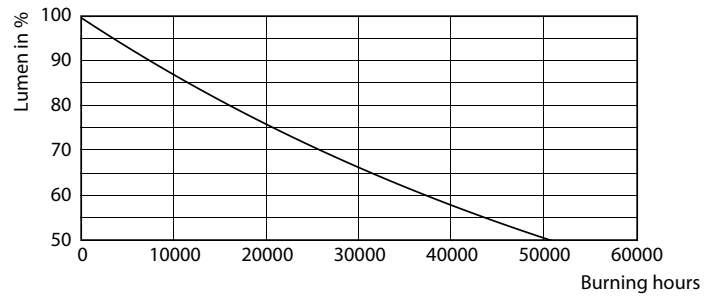

LEDSpot 33W E26 PAR38

