

TBX-CCT-810

VERSATILE RECESSED LIGHTING SERIES



NAME:

TYPE:

DATE:

NOTES:

SPECIFICATIONS

LIGHT UNIT:	Aluminum construction with powder coat paint to prevent discoloring and rusting.
WIRING:	24" BX cable, which is installed in a junction box. An installation cable is also included, which offers a "no worries" method of wiring the luminaire while not having to hold the unit.
INSTALLATION:	Ideal for ceiling installations with no housing required. Steel spring clip for easy installation. Suitable for installation in t-grid and drop ceiling applications. The Triad Series is ideal for commercial applications, where a replacement CFL/PL, fluorescent or incandescent fixture is needed.
OPTICS:	Integrated LED technology uses light guided reflector to distribute light and optimize high level of delivered lumens.
ELECTRICAL & PHASE CONTROL:	Easily connected to a 120V power supply via provided UL recognized driver. Standard 120-277V, 0-10V dimming driver. Dimming down to 10% with most standard LED dimmers (see list of approved dimmers). Ambient operating temperature: -40°C (-40°F) to +40°C (+104°F). IC , WET location and Air-Tight rated. AirTight ASTM E283 rated. Certifications: This product is ETL listed in USA & Canada, certified to UL standard 1598 and CSA standard C22.2 No. 250.0-08

CUTTING HOLE:	7.75" to 9.375" (195 to 240mm)
MOUNTING PLATE:	MPHB 800
BEAM ANGLE:	95°
SELECTABLE COLOR TEMPERATURE:	3K - 4K - 5K
CRI:	90+
LUMEN OUTPUT:	Selectable 1050-1700-2500 lumens
DIMMABLE:	Yes
WATTS:	Selectable 12-20-30W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120-277V, 0-10V Dimming


APPLICATIONS

The Triad Series is a versatile lighting product offering the option of varied color temperature, wattage, and lumen output level, in ONE single unit. Whether it is a remodel or new construction installation, this unit is well suited for indoor or outdoor in various commercial applications. These may include property management, healthcare, retail, office, hospitality and many more.

TBX-CCT-810

VERSATILE RECESSED LIGHTING SERIES

DIMENSIONS

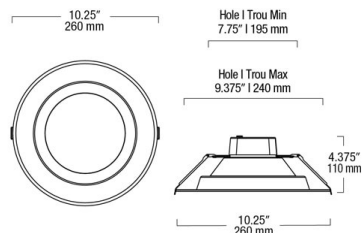

ACCESSORIES



MOUNTING PLATE

Versatile square mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.



ADJUSTABLE MOUNTING PLATE

Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.



MOUNTING PLATE WITH ADJUSTABLE HANGER BARS

Versatile adjustable mounting plate allows for installation of all models of ndr recessed lighting products. refer to our mounting plate compatibility chart to ensure the proper mounting plate is selected.



GOOF RINGS

This goof ring is used when the ceiling hole is wider than the retrofit light unit being installed. refer to our goof ring compatibility chart to ensure the proper goof ring is selected.

RATINGS

AIRTIGHT
RATED



IC
RATED



ORDERING GUIDE

Triad TBX-CCT-810 SERIES

Series	Wattage	Selectable Color Temperature	Finish
TBX-CCT-810	LOW - 12W MED - 20W HIGH - 30W	3000K/4000K/5000K	WH White

Notes: Configure product using **BOLD** options: Ex: **TBX-CCT-810-WH**