

OS110LED

OUTDOOR SECURITY SOLUTIONS FOR RESIDENTIAL APPLICATION



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

LIGHT UNIT:	Rugged cast-aluminum, corrosion-resistant housing with dark bronze or white powder paint for lasting durability.
	LED lamp heads and motion sensor are thermally isolated from the driver that is located in the rear housing, promoting a long service life.
	Adjustable Photocell Sensitivity
	The Premium PIR motion sensor is fully adjustable for ideal positioning. It offers 200 degree wide angle forward detection, 80 degree downward perimeter detection and 70 feet detection range.
	Lenses and motion sensor are sealed to keep out moisture, dirt and bugs.
	LEDs maintain 70% of light output at 50,000 hours of service life.
INSTALLATION:	Crossbar and hardware provided.
	Wet location listed for mounting 4 feet above ground.
	Tool-less adjustable heads allow for precise aiming.
	Dual mount system: Can be mounted on walls or soffits
ELECTRICAL:	Energy efficient LED provides 2300 lumens, consumes 27W utilizing 120V 60Hz driver.
	Selectable Color Temperature, choice of 3000K or 4000K
	Rated for outdoor installations, -40°C minimum ambient.
	LISTINGS UL/cUL listed Listed to U.S. and Canadian safety standards for wet locations.

COLOR TEMPERATURE:	3K or 4K Selectable
OPERATING TEMPERATURE:	-40°C + 40°C
CRI:	70+
LUMEN OUTPUT:	2400LM
WATTS:	23W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V
MOTION SENSOR DETECTION RANGE:	70' (21m)


APPLICATIONS

The high performance LED oval twin-head security light offers security and general lighting for outdoor residential and commercial applications. Long lasting, energy saving illumination ideal for yards, driveways, walkways, lots and loading areas.

OS110LED

OUTDOOR SECURITY SOLUTIONS FOR RESIDENTIAL APPLICATION

DIMENSIONS

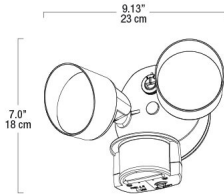

RATINGS



ORDERING GUIDE

OS110 SERIES

Series	Finish
OS110LED-2HO	DB Dark Bronze
	WH White

Notes: Configure product using **BOLD** options: Ex: **OS110LED-2HO-WH**