

LSLMS-2FT-WH

Low Profile Strip Light



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

WIRING:	<p>Hardwire only. Installs easily to ceiling or wall. It may also be installed over a junction box using a canopy plate for an octagonal junction box.</p> <p>Manufactured as a two-part unit; easily removed front panel and a wire back housing to allow for ease of installation.</p>
HOUSING DETAILS:	<p>The housing channel is formed steel with durable poly carbonate end caps, with multiple 1/2" knockout locations for ease of installation.</p> <p>The motion sensor is a PIR sensor with a detection range of 13'(4m) to 19'(6m) and a time delay of 3 minutes. Sensing no movement within that time period, the unit will shut off automatically.</p>
OPTICS:	<p>Offered with an acrylic frosted diffuser lens and LED strip technology to distribute light and optimize delivered high level of lumens.</p>
ELECTRICAL:	<p>Easily connected to a 120-277V power supply via provided UL recognized driver.</p> <p>Non-dimmable</p> <p>DAMP LOCATIONS rated</p> <p>Certifications: This product is ETL and Energy Star listed in USA and Canada.</p>
LENS:	<p>Viper Light Strip has a frosted diffuser providing a uniform and widespread illumination.</p>

COLOR TEMPERATURE:	4k
CRI:	80+
LUMEN OUTPUT:	1575LM
DIMMABLE:	No
WATTS:	15W
LED LIFE:	54,000 hours
WARRANTY:	5 years
VOLTAGE:	120-277V
HEIGHT:	1.80" (4.6cm)
LENGTH:	22.80" (57.9cm)
WIDTH:	1.60" (4.1cm)
INTEGRATED MOTION SENSOR:	Yes
MOTION SENSOR DETECTION RANGE:	13' - 19' (4m-9m)


APPLICATIONS

Low-profile LED strip light equipped with a PIR motion sensor. Ideal for many applications including corridors, laundry rooms, workshops, utility work areas, closet spaces and stairways.

LSLMS-2FT-WH

Low Profile Strip Light

DIMENSIONS

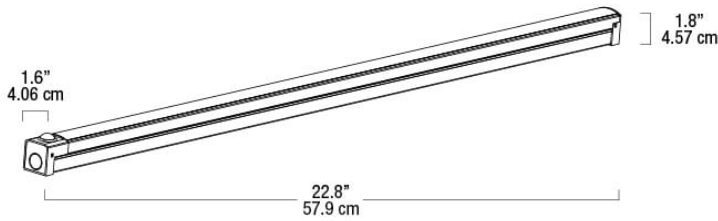

ACCESSORIES



5" JUNCTION BOX COVER PLATE

This j-box cover has been designed to work with the viper series of products. it will protect an existing electrical j-box to prevent unsightly installation and potential damage. once installed, the j-box cover plate offers a clean and neat appearance for the light unit. fits to cover standard octagon junction box. painted white finish with 2 painted white screws included. 1/2" centre knockout hole for easy wiring and installation.

RATINGS



ORDERING GUIDE

VIPER STRIP LIGHT SERIES

Series	Length	Color Temperature	Finish
LSLMS	2FT	4K 4000K/80CRI/15W	WH White

Notes: Configure product using **BOLD** options: Ex: **LSLMS-2FT-WH**