

# LSLMS-4FT-WH

Low Profile Strip Light



|        |  |
|--------|--|
| NAME:  |  |
| TYPE:  |  |
| DATE:  |  |
| NOTES: |  |

**SPECIFICATIONS**

|                         |  |
|-------------------------|--|
| <b>WIRING:</b>          | <p>Hardwire only. Installs easily to ceiling or wall. It may also be installed over a junction box using a canopy plate for an octagonal junction box.</p> <p>Manufactured as a two-part unit; easily removed front panel and a wire back housing to allow for ease of installation.</p>   |
| <b>HOUSING DETAILS:</b> | <p>The housing channel is formed steel with durable poly carbonate end caps, with multiple 1/2" knockout locations for ease of installation.</p> <p>The motion sensor is a PIR sensor with a detection range of 13'(4m) to 19'(6m) and a time delay of 3 minutes. Sensing no movement within that time period, the unit will shut off automatically.</p> |
| <b>OPTICS:</b>          | <p>Offered with an acrylic frosted diffuser lens and LED strip technology to distribute light and optimize delivered high level of lumens.</p>   |
| <b>ELECTRICAL:</b>      | <p>Easily connected to a 120-277V power supply via provided UL recognized driver.</p> <p>Non-dimmable</p> <p>DAMP LOCATIONS rated</p> <p>Certifications: This product is ETL and Energy Star listed in USA and Canada.</p>   |
| <b>LENS:</b>            | <p>Viper Light Strip has a frosted diffuser providing a uniform and widespread illumination.</p>   |

|                                |                   |
|--------------------------------|-------------------|
| COLOR TEMPERATURE:             | 4k                |
| CRI:                           | 80+               |
| LUMEN OUTPUT:                  | 2625LM            |
| DIMMABLE:                      | No                |
| WATTS:                         | 25W               |
| LED LIFE:                      | 54,000 hours      |
| WARRANTY:                      | 5 years           |
| VOLTAGE:                       | 120-277V          |
| HEIGHT:                        | 1.80" (4.6cm)     |
| LENGTH:                        | 46.50" (118.1cm)  |
| WIDTH:                         | 1.60" (4.1cm)     |
| INTEGRATED MOTION SENSOR:      | Yes               |
| MOTION SENSOR DETECTION RANGE: | 13' - 19' (4m-9m) |


**APPLICATIONS**

Low-profile LED strip light equipped with a PIR motion sensor. Ideal for many applications including corridors, laundry rooms, workshops, utility work areas, closet spaces and stairways.

# LSLMS-4FT-WH

Low Profile Strip Light

## DIMENSIONS

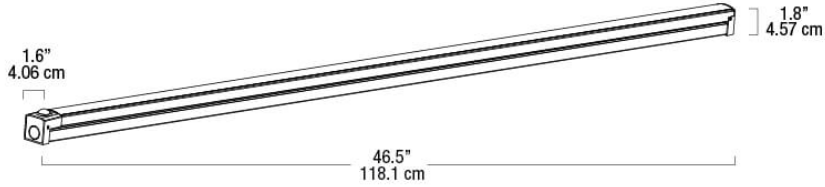

## ACCESSORIES



### 5" JUNCTION BOX COVER PLATE

This j-box cover has been designed to work with the viper series of products. it will protect an existing electrical j-box to prevent unsightly installation and potential damage. once installed, the j-box cover plate offers a clean and neat appearance for the light unit. fits to cover standard octagon junction box. painted white finish with 2 painted white screws included. 1/2" centre knockout hole for easy wiring and installation.

## RATINGS



## ORDERING GUIDE

### VIPER STRIP LIGHT SERIES

| Series   | Length | Color Temperature  | Finish   |
|--|--------|--------------------|----------|
| LSLMS  | 4FT    | 4K 4000K/80CRI/25W | WH White |
| <b>Notes:</b> Configure product using <b>BOLD</b> options: Ex: <b>LSLMS-4FT-WH</b> |        |                    |          |