

**FM60-LED**

FLUSH MOUNT



NAME:

TYPE:

DATE:

NOTES:

**SPECIFICATIONS**

WIRING:	Installs easily in traditional junction boxes ( 3" or 4" ).
HOUSING DETAILS:	<p>This flush mount unit uses metal housing.</p> <p>The Apollo Series is available with or without the motion sensor. The motion sensor is a PIR sensor, with a detection range of 3' ( 1M ) to 6' ( 2M ) and a time delay of 5 minutes. Sensing no movement within that time period, the unit will shut off automatically.</p>
OPTICS:	LED technology delivers 650 lumens ( 3K version ) and 890 lumens ( 4K version ).
ELECTRICAL:	<p>Easily connected to a 120V power supply via provided UL recognized driver.</p> <p>DAMP LOCATIONS and DIMMABLE. Motion sensor model is non-dimmable.</p> <p>Dimming down to 10% with most standard LED dimmers ( see list of approved products ).</p> <p>Certified for use in closets.</p> <p>Certifications: This product is ETL and Energy Star listed in USA &amp; Canada.</p>
LENS:	White decorative acrylic frosted lens provides an even light distribution.

COLOR TEMPERATURE:	3K - 4K
OPERATING TEMPERATURE:	-20°C + 40°C
CRI:	80+
LUMEN OUTPUT:	650 lumens
DIMMABLE:	Yes
WATTS:	9W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V
DIAMETER:	5.75" (146.1mm)
HEIGHT:	1.00" (25.4mm)
INTEGRATED MOTION SENSOR:	No


**APPLICATIONS**

The Apollo series of LED flush mount fixtures by NDR is suitable for closets, storage areas, pantries and utility rooms. Its low profile offers an affordable and stylish design with low energy costs. The diffuser may be easily removed for installation and cleaning. Ideal for interior ceiling or wall installations in residential applications.

**FM60-LED**

FLUSH MOUNT

## DIMENSIONS

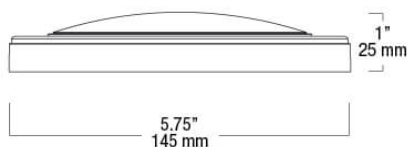

## RATINGS



## ORDERING GUIDE

**APOLLO FM60 SERIES**

Series	Color Temperature	Finish
FM60-0510	3K 3000K/80CRI/9W	WH White
	4K 4000K/80CRI/9W	

**Notes:** Configure product using **BOLD** options: Ex: **FM60-0510-3K-WH**