

**WLLED48**

COBRA LOW PROFILE WRAP AROUND



NAME:	
TYPE:	
DATE:	
NOTES:	

**SPECIFICATIONS**

<b>WIRING:</b>	Hardwire only. Installs easily in traditional junction boxes (3" or 4"). Also features an internal junction box when the application requires linking multiple units in series.
<b>HOUSING DETAILS:</b>	Metal housing with durable plastic end caps. Mounts flush to a wall or ceiling.
<b>OPTICS:</b>	LED strip technology uses a light guided reflector to distribute light and optimize high level of delivered lumens. Integrated LED - no bulbs required. Maintenance free LED ceiling light.
<b>ELECTRICAL:</b>	Easily connected to a 120-277V power supply via provided UL recognized driver.  NON-IC and DAMP LOCATIONS rated.  Certifications : This product is ETL and Energy Star listed in USA and Canada.
<b>LENS:</b>	A light guide reflector in combination with a white acrylic frosted lens, provides an even light distribution.

COLOR TEMPERATURE:	4k
CRI:	80+
LUMEN OUTPUT:	4000 lumens
DIMMABLE:	No
WATTS:	40W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120-277V
HEIGHT:	2.6" (6.60 cm )
LENGTH:	47.4" (120.40 cm )
WIDTH:	5.5" ( 13.97 cm )
INTEGRATED MOTION SENSOR:	No


**APPLICATIONS**

Low-profile LED wrap around with a frosted diffuser providing a widespread, uniform illumination. Ideal for many applications, including corridors, laundry rooms, kitchens, break rooms, utility work areas and stairways. Ideal for interior ceiling or wall installations in residential or commercial applications.

**WLLED48**

COBRA LOW PROFILE WRAP AROUND

**DIMENSIONS**

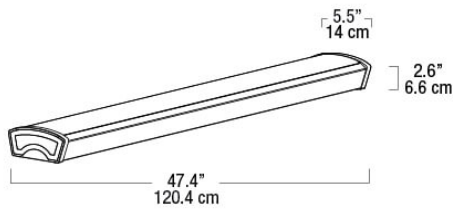

**RATINGS**



**ORDERING GUIDE**

**COBRA WRAP LIGHT SERIES**

Series	Length	Color Temperature	Finish
WLLED	48	4K 4000K/80CRI/40W	WH White
<b>Notes:</b>	Configure product using <b>BOLD</b> options: Ex: <b>WLLED48-4K-WH</b>		