

UNL50DIM-CCT-21

Under Cabinet with Selectable Color Temperature



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

WIRING:	Offering a spacious wiring cavity and multiple 1/2" knockout locations, this unit may be wired quickly and easily.
HOUSING DETAILS:	Extruded aluminum fixture includes an integrated LED driver, ON/OFF switch, Selectable Color switch, multiple 1/2" knockout locations and a diffused glass lens, which allows for even light distribution. Mounting hardware included.
ELECTRICAL:	Easily connected to a 120V power supply, hardwire only. DAMP LOCATIONS rated. Dimmable Certifications: This product is ETL listed in USA and Canada.

COLOR TEMPERATURE:	3K - 4K - 5K CCT
CRI:	80+
LUMEN OUTPUT:	1000 LM
DIMMABLE:	Yes
WATTS:	14W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V
HEIGHT:	1.25" (31.75mm)
LENGTH:	21.0" (533.4mm)
WIDTH:	3.5" (88.9mm)


APPLICATIONS

The Lucia CCT series offers a cost-effective LED lighting solution with multiple knockout locations for easy and quick installation. It includes a diffused frosted lens, which allows for an even light distribution. Ideal for use under cabinets, closets and work stations and more.

UNL50DIM-CCT-21

Under Cabinet with Selectable Color Temperature

DIMENSIONS

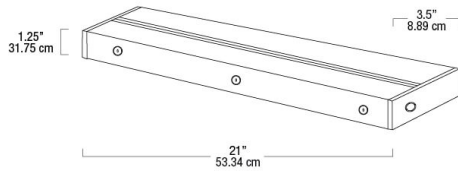

RATINGS



ORDERING GUIDE

LUCIA UNL50DIM-CCT SERIES

Series	Length	Color Temperature	Finish
UNL50DIM-CCT	8 8 inch	3000K-4000K-5000K/80CRI/5W	WH White
	12 12 inch	3000K-4000K-5000K/80CRI/7W	
	21 21 inch	3000K-4000K-5000K/80CRI/14W	
	30 30 inch	3000K-4000K-5000K/80CRI/18W	

Notes: Configure product using **BOLD** options: Ex: **UNL50DIM-CCT-21WH**