

**UNL50DIM-CCT-30**

Under Cabinet with Selectable Color Temperature



NAME:	
TYPE:	
DATE:	
NOTES:	

**SPECIFICATIONS**

<b>WIRING:</b>	Offering a spacious wiring cavity and multiple 1/2" knockout locations, this unit may be wired quickly and easily.
<b>HOUSING DETAILS:</b>	Extruded aluminum fixture includes an integrated LED driver, ON/OFF switch, Selectable Color switch, multiple 1/2" knockout locations and a diffused glass lens, which allows for even light distribution. Mounting hardware included.
<b>ELECTRICAL:</b>	Easily connected to a 120V power supply, hardwire only. DAMP LOCATIONS rated. Dimmable Certifications: This product is ETL listed in USA and Canada.

COLOR TEMPERATURE:	3K - 4K - 5K CCT
CRI:	80+
LUMEN OUTPUT:	1250 LM
DIMMABLE:	Yes
WATTS:	18W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V
HEIGHT:	1.25" (31.75mm)
LENGTH:	30.0" (762.0mm)
WIDTH:	3.5" (88.9mm)


**APPLICATIONS**

The Lucia CCT series offers a cost-effective LED lighting solution with multiple knockout locations for easy and quick installation. It includes a diffused frosted lens, which allows for an even light distribution. Ideal for use under cabinets, closets and work stations and more.

# UNL50DIM-CCT-30

Under Cabinet with Selectable Color Temperature

## DIMENSIONS

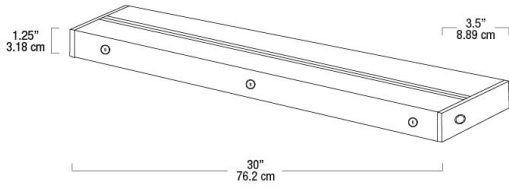

## RATINGS



## ORDERING GUIDE

### LUCIA UNL50DIM-CCT SERIES

Series	Length	Color Temperature	Finish
UNL50DIM-CCT	8 8 inch	3000K-4000K-5000K/80CRI/5W	WH White
	12 12 inch	3000K-4000K-5000K/80CRI/7W	
	21 21 inch	3000K-4000K-5000K/80CRI/14W	
	30 30 inch	3000K-4000K-5000K/80CRI/18W	

Notes: Configure product using **BOLD** options: Ex: **UNL50DIM-CCT-30WH**