

UNS70DIM-CCT-12

Swivel Under Cabinet



NAME:	
TYPE:	
DATE:	
NOTES:	

SPECIFICATIONS

WIRING:	Offering a spacious wiring cavity and multiple 1/2" knockouts, this unit may be wired quickly and easily.
HOUSING DETAILS:	Extruded aluminum fixture includes an integrated LED driver, ON/OFF switch, a selectable color temperature switch, and a diffused frosted glass lens, which allows for event light distribution. Mounting hardware included.
ELECTRICAL:	Easily connected to a 120-277V power supply, hardwire only. DAMP LOCATIONS rated. Intensité réglable Certifications: This product is ETL listed in USA and Canada

COLOR TEMPERATURE:	3K - 4K - 5K CCT
CRI:	80+
LUMEN OUTPUT:	500 LM
DIMMABLE:	Yes
WATTS:	7 W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120-277V
HEIGHT:	1.25" (31.75mm)
LENGTH:	12" (304.8mm)
WIDTH:	3.5" (88.9mm)


APPLICATIONS

This LED under cabinet series offer lower energy consumption and longer life over incandescent and flourescent lighting. Ideal for use under cabinets, closets and workstations.

UNS70DIM-CCT-12

Swivel Under Cabinet

DIMENSIONS

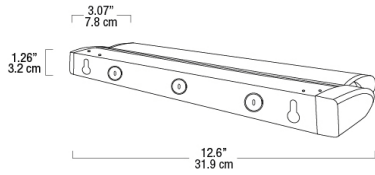

RATINGS



ORDERING GUIDE

ISA UNS70DIM-CCT SERIES

Series	Length	Color Temperature	Finish
UNS70DIM-CCT	12 12 inch	3000K-4000K-5000K/80CRI/7W	WH White
	21 21 inch	3000K-4000K-5000K/80CRI/14W	
	30 30 inch	3000K-4000K-5000K/80CRI/18W	

Notes: Configure product using **BOLD** options: Ex: **UNS70DIM-CCT-12WH**