


SHOCKWAVE™ LINEMAN’S IMPACT AUGER BITS

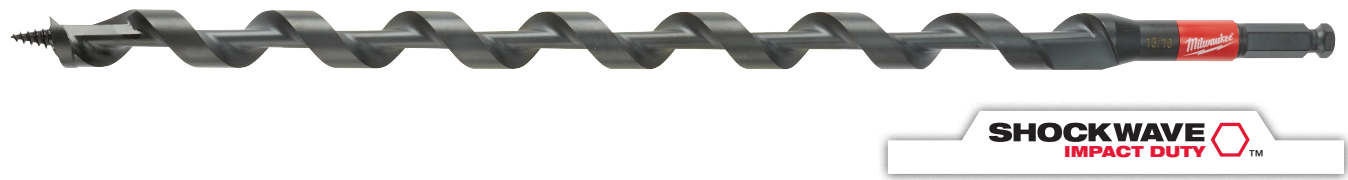

OVERVIEW


The SHOCKWAVE™ Lineman's Impact Auger Bits are engineered to deliver cleaner, faster holes in wooden utility poles. They feature a single-spur design, which scores the edge of the hole, creating a cleaner finish that allows bolts to slide through without resistance. The bits are coated with a reinforced anti-friction PTFE coating for overall smoother drilling and easier removal of the bit from the pole. The aggressive feed screw and cutting edge pull the bit through the material while the optimized wide flute geometry quickly ejects the chips to clear the hole and reduce clogs, leading to overall faster drilling speeds.

FEATURES

- Engineered for the Power Utility Lineman to drill cleaner, faster holes in wooden utility poles
- Single-spur Design scores the hole for a cleaner finish
- Reinforced Anti-Friction PTFE Coating for overall smoother drilling

SHOCKWAVE™ LINEMAN'S IMPACT AUGER BITS			
Description	18" Part No.	24" Part No.	30" Part No.
3/8" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6700	48-13-6800	–
1/2" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6702	48-13-6802	–
9/16" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6703	48-13-6803	–
5/8" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6704	48-13-6804	48-13-6904
11/16" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6705	48-13-6805	48-13-6905
13/16" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6707	48-13-6807	48-13-6907
15/16" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6709	48-13-6809	48-13-6909
1" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6710	48-13-6810	–
1-1/16" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6711	48-13-6811	–
1-1/8" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6712	48-13-6812	–
1-1/4" SHOCKWAVE™ Lineman's Impact Auger Bit	48-13-6713	48-13-6813	–
11/16" SHOCKWAVE™ Lineman's Impact Auger Bits (25 pk)	48-13-6795	–	–
13/16" SHOCKWAVE™ Lineman's Impact Auger Bits (25 pk)	48-13-6797	–	–
15/16" SHOCKWAVE™ Lineman's Impact Auger Bits (25 pk)	48-13-6799	–	–

 SHIP AUGER BITS



OVERVIEW

The MILWAUKEE® Ship Auger Bit drills through up to 2X the nails of competitive auger bits without needing resharpener. Drill into clean or nail-embedded wood with confidence when installing Romex wire, PEX water lines, rebar, bolts, and rope in piers, playground equipment, and landscaping. The flutes are wider for maximum chip removal, even in deep holes. The polished and coated flute finish means chips won’t stick to the bit, even when drilling in material that contains sap or glue. The through-center cutting design creates a more solid striking point against nails compared to the competitions’ ahead-of-center and behind-center designs. The longer shaft length makes it easy to drill deeper or overhead without an extension.


FEATURES

- Durable: Hardened, one-face 20° rake angle design enhances nail resistance, chip removal, and fast, easy sharpening
- Fast Chip Removal: Nonstick, polished, and coated flutes eliminate costly cleaning time
- Impact-Rated Shank: Strong enough to use with an impact wrench

SHIP AUGER BITS		
Description	6"	18"
3/8" Ship Auger Bit	48-13-0373	48-13-5500
7/16" Ship Auger Bit	–	48-13-5520
1/2" Ship Auger Bit	48-13-0503	48-13-5540
9/16" Ship Auger Bit	–	48-13-5560
5/8" Ship Auger Bit	48-13-0623	48-13-5620
11/16" Ship Auger Bit	48-13-0683	48-13-5680
3/4" Ship Auger Bit	48-13-0753	48-13-5750
13/16" Ship Auger Bit	48-13-0813	48-13-5810

SHIP AUGER BITS		
Description	6"	18"
7/8" Ship Auger Bit	48-13-0873	48-13-5870
15/16" Ship Auger Bit	48-13-0933	48-13-5930
1" Ship Auger Bit	48-13-1003	48-13-6000
1-1/16" Ship Auger Bit	48-13-1063	48-13-6010
1-1/8" Ship Auger Bit	48-13-1123	48-13-6120
1-1/4" Ship Auger Bit	48-13-1253	48-13-6250
1-3/8" Ship Auger Bit	48-13-1373	48-13-6370
1-1/2" Ship Auger Bit	48-13-1503	48-13-6500

SHIP AUGER BIT SET

SHIP AUGER BIT SET		
Description	Includes	Part No.
	(1) 1/2" Ship Auger Bit (1) 3/4" Ship Auger Bit (1) 1" Ship Auger Bit (1) Carrying Case	48-13-3000