

FEATURES & SPECIFICATIONS

INTENDED USE

Provides general illumination in residential and light commercial applications. Ideal for use in offices and all rooms in the home. **If required for commercial application or operation more than eight (8) hours per day, consult factory for available options.**

CONSTRUCTION

Decorative contoured distinctive linear design complements a variety of decors. Durable, milk white acrylic diffuser provides wide spread, uniform illumination and allows easy access for cleaning and maintenance. Available in four sizes: 1'x4', 1-1/2'x2', 2'x2', or 1-1/2'x4'.

OPTICS

Utilizes (2) or (4) linear T8 fluorescent lamps for energy efficiency, superior color rendering and long life (not included).

ELECTRICAL

Standard with electronic ballast (120 volt, 60 Hz) ensures no flickering and quiet operation without interfering with other electronics. Also available in other ballast configurations.

For use with non-dimmable switches only.

INSTALLATION

All mounting hardware included.

LISTINGS

UL Listed to US and Canadian safety standards. For non-RE ballast fixtures, UL (standard) and for CSA certified (see options).

WARRANTY

2-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application. Specifications subject to change without notice.

Catalog Number
Notes
Type

Indoor General Purpose


Litepuff Linear Flush Mount

Linear T8 Fluorescent



DIMENSIONS						
Nominal size	Lamp configuration	Model number	Number of lamps	(A) Width inches (cm)	(B) Length inches (cm)	(C) Extension inches (cm)*
1' x 4'		10640	(2) 32W Linear T8	11-1/4" (28.6)	51-1/2" (130.8)	5-1/2" (14.0)
1-1/2' x 2'		10641	(4) 17W Linear T8	16-5/8" (42.2)	27-1/2" (69.5)	5-1/2" (14.0)
2' x 2'		10651	(2) 31W Linear T8	27" (68.6)	27-3/8" (69.5)	5-1/2" (14.0)
1-1/2' x 4'		10642	(4) 32W Linear T8	16-5/8" (42.2)	51-1/2" (130.8)	5-1/2" (14.0)

*Extension from ceiling.
All dimensions are inches (centimeters) unless otherwise indicated.

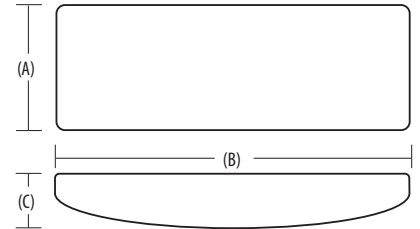

ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

Example: 10640 32 MVOLT GEB

Series ^{1,2}	Residential ballast ⁴	Lamp ⁵	Ballast/Voltage ⁷	Options	
10640 1'x4' - (2) 32W linear T8 lamps	(blank) Other voltage and ballast types available (see ballast/voltage)	(blank) RE ballast fixtures only	(blank) RE ballast fixtures only	GEB Electronic ballast, <20%THD	
10641 1-1/2'x2' - (4) 17W linear T8 lamps	RE 120 volt residential electronic ballast (standard)	Non-RE ballast fixtures only	MVOLT Multi-volt	GEB10IS T8 electronic ballast, <10% THD, instant start	
10651 2'x2' - (2) 31W T8 U-lamps ³		17 17W T8 (2' fixtures only)		120 120V	GEB10RS T8 electronic ballast, 10% THD, rapid start
10642 1-1/2'x4' - (4) 32W linear T8 lamps		U31 31W T8-U (1-5/8" leg) ⁶		277 277V	CSA CSA Certified ⁸ Consult factory for other options and accessories
		U316 31W T8-U (6" leg) ⁶		347 347V	
		32 32W T8 (4' fixtures only)	Others available. Consult factory.		

Replacement Parts: Order as separate catalog number.	
DPUFF	1' x 4' white acrylic diffuser
D15PUFF2	1-1/2' x 2' white acrylic diffuser
D2PUFF2	2' x 2' white acrylic diffuser
D15PUFF	1-1/2' x 4' white acrylic diffuser

Notes

- Lamps not included.
- Use with non-dimmable switches only.
- Lamp configuration for RE fixtures is standard U316.
- Residential electronic ballast standard and requires RE designation.
- No designation for lamp type is required on RE ballast fixtures.
- Only available with 2'x2' fixtures (Also can be ordered on REballast 2x2 fixtures).
- No designation for ballast/voltage type is required on RE ballast fixtures.
- CSA standard on RE ballast fixtures.

Litepuff Linear Flush Mount

PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.