



A-Shape LED

16A19/PER/930/P/E26/DIM 6/1FB T20

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data


General Information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	16-100W
Light Technical	
Color Code	930 [CCT of 3000K]
Beam Angle (Nom)	250 °
Initial lumen (Nom)	1600 lm
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	100.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	16 W
Lamp Current (Nom)	135 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	90 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Frosted
Approval and Application	
Energy Efficiency Label (EEL)	Not applicable
Energy Consumption kWh/1000 h	- kWh
Product Data	
Order product name	16A19/PER/930/P/E26/DIM 6/1FB T20
EAN/UPC - Product	046677561079
Order code	561076
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929002385604

A-Shape LED

Net Weight (Piece) 0.060 kg


Dimensional drawing

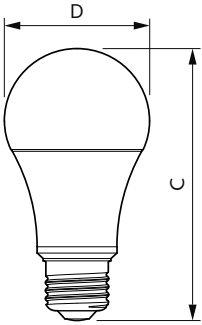


Bulb A19 120V 16-100W 1600lm 3000K E26 D

Product	D	C
16A19/PER/930/P/E26/DIM 6/1FB T20	60 mm	112 mm


Photometric data

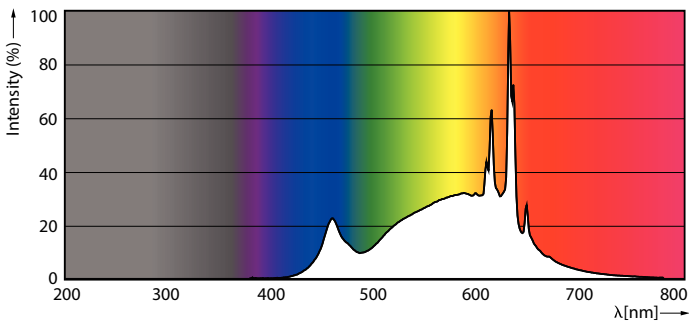

LEDbulb 16W A19 E26 930 FR

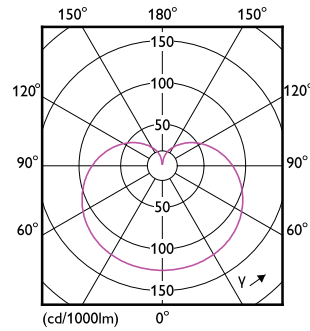

LEDbulb A19 16W E26 1600lm 930 FR


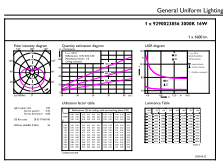


General Parameters (1) Page Lighting (1) Page 11

LEDbulb 16W A19 E26 930 FR

A-Shape LED

Lifetime

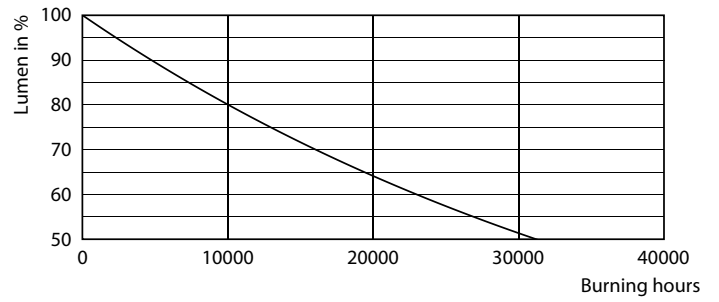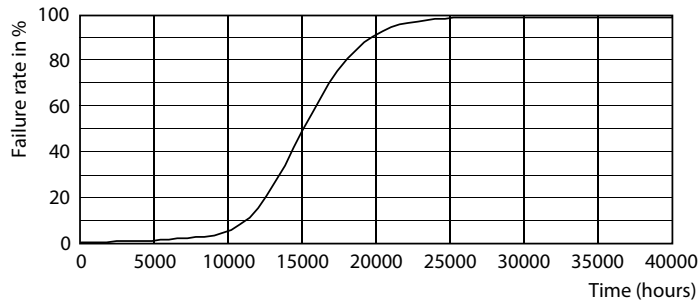

15K LED

15K LMP

