



T8

12T8/COR/48-840/MF18/G 10/1

Our TLEDs are available in InstantFit (Type A / Type C) or MainsFit (Ballast bypass / Type B) versions. The InstantFit lamps work on a broad variety of ballasts and LED drivers. Only InstantFit has over 15,000 lamp & ballast combinations delivering even light output, energy savings and a long lifetime. Our MainsFit products feature a double-ended design, simplifying installation while a proprietary safety circuit minimizes a shock risk. Lamp sizes range from 2-foot to 8-foot and U-bend with a variety of lumen outputs.

Product data

General Information	
Cap-Base	G13 [Medium Bi-Pin Fluorescent]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	12-32W
Light Technical	
Color Code	840 [CCT of 4000K]
Beam Angle (Nom)	240 °
Luminous Flux (Nom)	1800 lm
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4000 K
Luminous Efficacy (rated) (Nom)	150.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz

Power (Nom)	12 W
Lamp Current (Max)	102 mA
Lamp Current (Min)	48 mA
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	120-277 V
Temperature	
T-Ambient (Max)	45 °C
T-Ambient (Min)	-20 °C
T-Storage (Max)	65 °C
T-Storage (Min)	-40 °C
T-Case Maximum (Nom)	70 °C
Controls and Dimming	
Dimmable	Limited

T8

Mechanical and Housing

Bulb Finish	Frosted
Bulb Material	Glass
Product Length	1200 mm
Bulb Shape	Tube, double-ended


Approval and Application

Energy Efficiency Label (EEL)	Not applicable
Energy Saving Product	Yes
Approval Marks	RoHS compliance UL certificate DLC compliance
Energy Consumption kWh/1000 h	- kWh

Product Data

Order product name	12T8/COR/48-840/MF18/G 10/1
EAN/UPC - Product	046677563509
Order code	929002484204
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002484204
Net Weight (Piece)	0.215 kg
Model Number	9290024842



Dimensional drawing

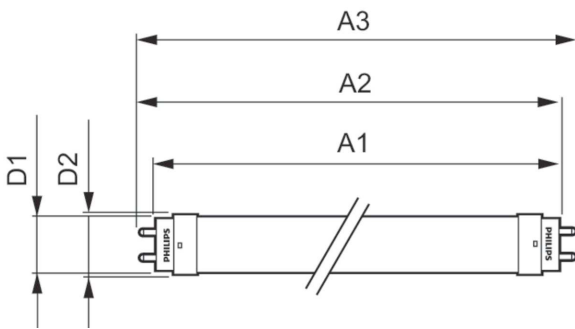

TLED T8 120-277V 12-32W 1800lm 4000K G13

Product	D1	D2	A1	A2	A3
12T8/COR/48-840/MF18/G 10/1	25.7 mm	28 mm	1198.2 mm	1205.3 mm	1212.4 mm


Photometric data

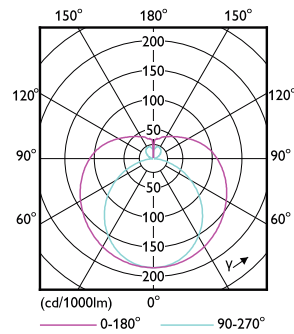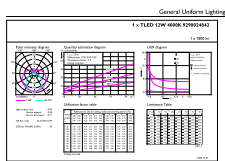

LEDtube COR 12W G13 1800lm 840


LEDtube COR 9,9W G13 1550lm

Photometric data

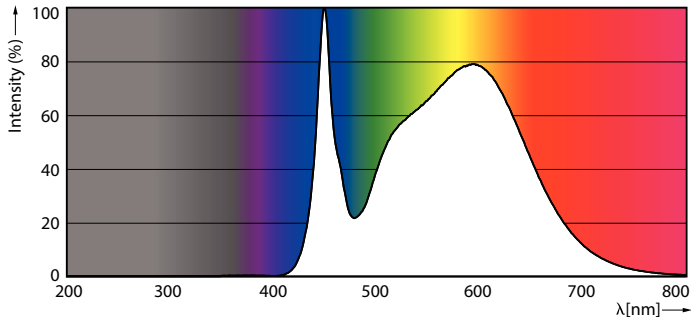

LEDtube COR 9,9W G13 1600lm 840


Lifetime

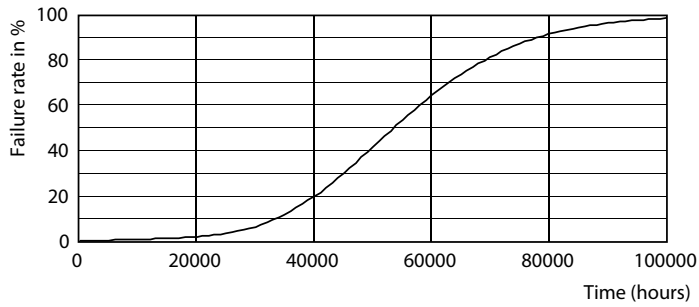

LEDtube 50K-LED



LEDtube 50K FailureRate-LED

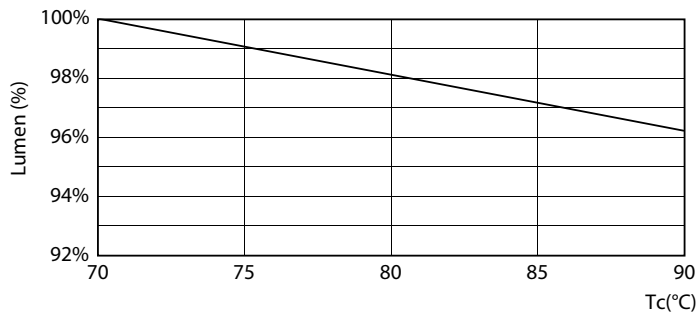

LEDtube COR 9,9W 50K LumenVsTc



LEDtube 50K-LMP

Lifetime



LEDtube 50K LifetimeVsTc-LED

