

SL6 - Indoor Diffusion LED Strip

Description

Diffusion SL-6 is a flexible 10mm wide linear LED strip. It is available in 16' and 100' rolls that can be cut every 6 LEDs (50mm or 2").

Note: SL6 needs to be installed in aluminum channel

Features

- 3M industrial strength adhesive tape
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 2' power feeds on both ends of every roll

Custom lengths available upon request


Specifications

- LED : 14.4 W/m (4.5 W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 120/m (36/ft)
- Power Input : 24V DC
- CRI > 91

Lumens

- 2700K = 1220 lm/m (366 lm/ft) ●
- 3000K = 1282 lm/m (384 lm/ft) ●
- 3400K = 1344 lm/m (402 lm/ft) ●
- 4100K = 1400 lm/m (420 lm/ft) ○

Custom Kelvins available upon request

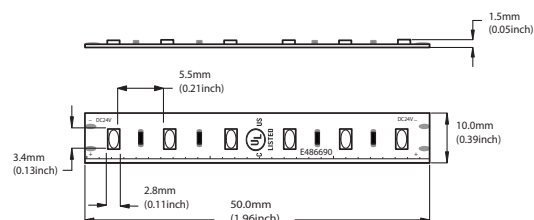

ORDERING CODE

ORDERING CODE	LENGTH	VOLTAGE	KELVIN
SL6-IN	xx	24V	xxxx
SL6-IN	16 ft	24 Volt	2700 K
	100 ft		3000 K
			3400 K
			4100 K

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

