

## SL3 - Outdoor Diffusion LED Strip

### Description

Diffusion SL-3 is a flexible 10mm wide linear LED strip. It is available in 16' and 32' rolls that can be cut every 6 LEDs (50mm or 2").

### Features

- Includes endcaps and mounting clips with screws
- Long life LED : 50,000 hrs
- Dimmable with dimming power supply
- 2' power feeds on both ends of every roll
- IP67

\*Custom lengths available upon request\*


### Specifications

- LED : 10 W/m (3 W/ft)
- Lamp Life : 50,000 hrs LM80
- LED/Meter : 120/m (36/ft)
- Power Input : 24V DC
- CRI > 91

### Lumens

- 2700K = 788 lm/m (236 lm/ft) ●
- 3000K = 820 lm/m (252 lm/ft) ●
- 3400K = 876 lm/m (263 lm/ft) ●
- 4100K = 908 lm/m (279 lm/ft) ○

\*Custom Kelvins available upon request\*

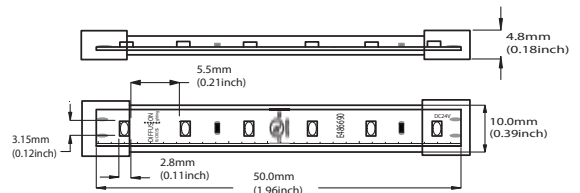

ORDERING  
CODE

LENGTH

VOLTAGE

KELVIN

SL3-OUT	xx	24V	xxxx
---------	----	-----	------

SL3-OUT

16 ft  
32 ft

24 Volt

2700 K  
3000 K  
3400 K  
4100 K

- 1 BIN SELECTION
- 2 STEP MACADAM ELLIPSE
- 3 TEST QUALITY CONTROL

